


Product Details

Product: 1305-BA02A

Description: 1305 AC Drive, 460VAC ,A02,3/4 HP,IP30, Type 1 - 1305,
or IP42 - 1305CFG,

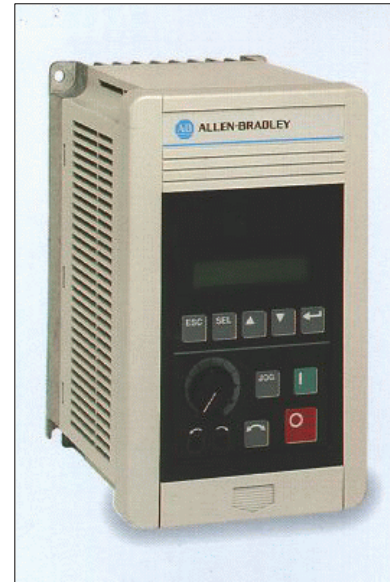

MOTOR DATA

Voltage	460V 60Hz
Phases	3 Phase
Torque	Constant Torque

DRIVE DATA

Max Output (Amps.)	1.6 A (380-460V)
Horsepower	3/4 HP
Enclosure Type	NEMA Type 1 - IP30
Standard Features	English Language Module
Frame Size	B