


Product Details

Product: 1305-BA03A

Description: 1305 AC Drive, 460VAC ,A03,1 HP,IP30, Type 1 - 1305,
or IP42 - 1305CFG,

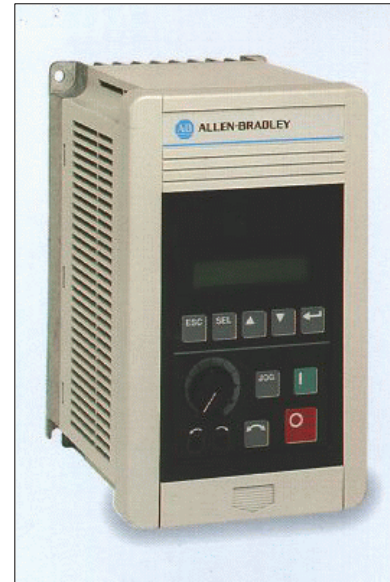

MOTOR DATA

Voltage	460V 60Hz
Phases	3 Phase
Torque	Constant Torque

DRIVE DATA

Max Output (Amps.)	2.3 A (380-460V)
Horsepower	1 HP
Enclosure Type	NEMA Type 1 - IP30
Standard Features	English Language Module
Frame Size	B