


# Product Details

## Product: 1305-BA04A

Description: 1305 AC Drive, 460VAC ,A04,2 HP,IP30, Type 1 - 1305,  
or IP42 - 1305CFG,

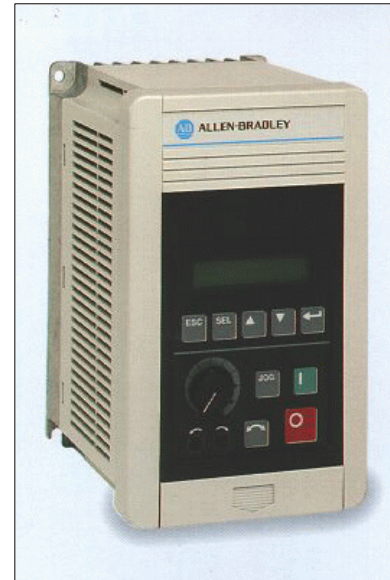

### ***MOTOR DATA***

---

Voltage	460V 60Hz
Phases	3 Phase
Torque	Constant Torque

### ***DRIVE DATA***

---

Max Output (Amps.)	4 A (380-460V)
Horsepower	2 HP
Enclosure Type	NEMA Type 1 - IP30
Standard Features	English Language Module
Frame Size	B