


Product Details and Certifications

Cross Reference RA Part Number: PN-D12978

→ Product: **140G-G-TLC13**

Description: Frame-G, Terminal Lug, Qty 3, FCCu 1x14-1/0(2.5-50)

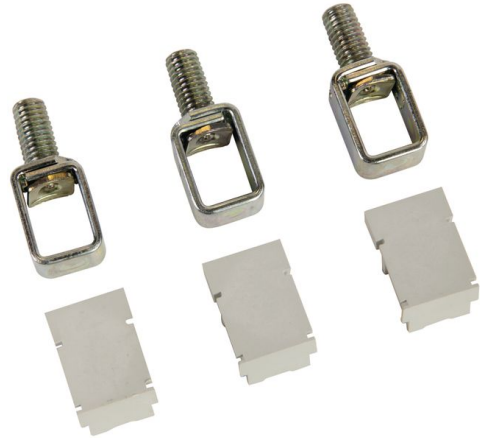

Representative Photo Only (actual product may vary based on configuration selections)

CIRCUIT BREAKER DATA

| | |
|------------------|---------------------|
| Bulletin Number | Bulletin 140G/140MG |
| Frame Size | G frame |
| Rated Current(A) | 125 A |

ACCESSORY ITEMS

| | |
|---------------|---|
| Terminal Lugs | Frame-G, Terminal Lug, Qty 3, FCCu 1x14-1/0(2.5-50) |
|---------------|---|


CERTIFICATIONS AND APPROVALS

| | |
|----------------------------------|---|
| UL | UL489 |
| CSA | CSA22.2 No. 5 |
| IEC | IEC 60947-2 |
| Certifications | UL Listed CSA Certified CE |
| For UL Certifications Directory: | http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm |

Molded Case Circuit Breakers

Accessories







Current Transformer for Neutral Current

|  <p><i>Representative Photo</i></p> | Rated Current [A] | Frame Size | Cat. No. |
|--|-------------------|---------------|---------------|
| | 300 | K ★ | 140G-K-NCTD30 |
| | 400 | K ★ | 140G-K-NCTD40 |
| | 600 | M ★ | 140G-M-NCTD60 |
| | 800 | M ★ | 140G-M-NCTD80 |
| | 400...1600 | N, NS | 140G-N-NCTE16 |
| 1000...3200 | R | 140G-R-NCTE30 | |

★ Order with connector (Cat. No. 140G-K-CC).

Mechanical Accessories

Terminal Lugs

| | Description | Frame Size | Cat. No. (Pkg. Qty. 3) | Cat. No. (Pkg. Qty. 4) |
|--|--|------------|------------------------|------------------------|
|  <p><i>Representative Photo</i></p> | Cu wire, MCCB only (1) 14...1/0 AWG or 2.5...70 mm ² | G | 140G-G-TLC13 | 140G-G-TLC14 |
| | Cu wire, MCP only (1) 14...1/0 AWG or 1.5...70 mm ² | | 140G-G-TLC13A | — |
| | Multiple cable - Cu wire (6) 14...2 AWG or 2.5...35 mm ² | | 140G-G-MTL63 | 140G-G-MTL64 |
| | Cu wire only (1) 14...1/0 AWG or 2.5...95 mm ² | | 140G-G-TLC13 | 140G-G-TLC14 |
|  <p><i>Representative Photo</i></p> | Multiple cable - Cu wire (6) 14...2 AWG or 2.5...35 mm ² | H | 140G-H-TLC13 | 140G-H-TLC14 |
| | Cu wire only (1) 14...1/0 AWG or 2.5...95 mm ² | | 140G-H-TLC13 | 140G-H-TLC14 |
| | Multiple cable - Cu wire (6) 14...2 AWG or 2.5...35 mm ² | | 140G-H-MTL63 | 140G-H-MTL64 |
| | Cu wire only (1) 14...1/0 AWG or 2.5...50 mm ² | | 140G-H-TLA13 | 140G-H-TLA14 |
|  <p><i>Representative Photo</i></p> | Al or Cu wire (1) 4...300 MCM or 25...150 mm ² | I | 140G-I-TLA1A3 | 140G-I-TLA1A4 |
| | Al or Cu wire (1) 10...250 MCM or 6...185 mm ² | | 140G-I-TLC13 | 140G-I-TLC14 |
| | Multiple cable - Cu wire (6) 12...2 AWG or 2.5...35 mm ² | | 140G-I-MTL63 | 140G-I-MTL64 |
| | Cu wire only (1) 10...350 MCM or 6...185 mm ² | | 140G-I-TLA13 | 140G-I-TLA14 |
|  <p><i>Representative Photo</i></p> | Al or Cu wire (1) 4...300 MCM or 25...150 mm ² | J | 140G-J-TLA1A3 | 140G-J-TLA1A4 |
| | Al or Cu wire (1) 6 (Al)/10 (Cu)...350 MCM or 2.5...185 mm ² (Al) | | 140G-J-TLA1B3 | 140G-J-TLA1B4 |
| | Cu wire only (1) 10...350 MCM or 6...185 mm ² | | 140G-J-TLC13 | 140G-J-TLC14 |
| | Multiple cable - Cu wire (6) 12...2 AWG or 2.5...35 mm ² | | 140G-J-MTL63 | 140G-J-MTL64 |
|  <p><i>Representative Photo</i></p> | Al or Cu wire (1) 250...500 MCM or 120...240 mm ² | K | 140G-K-TLA13 | 140G-K-TLA14 |
| | Al or Cu wire (2) 2/0...250 MCM or 95...120 mm ² | | 140G-K-TLA23 | 140G-K-TLA24 |
| | Cu wire only (1) 250...500 MCM or 120...240 mm ² | | 140G-K-TLC13 | 140G-K-TLC14 |
| | Cu wire only (2) 2/0...250 MCM or 95...120 mm ² | | 140G-K-TLC23 | 140G-K-TLC24 |
|  <p><i>Representative Photo</i></p> | Multiple cable - Cu wire (6) 6...1/0 AWG or 16...50 mm ² | M | 140G-K-MTL63 | 140G-K-MTL64 |
| | Al or Cu wire (2) 250...500 MCM or 120...240 mm ² | | 140G-M-TLA23 | 140G-M-TLA24 |
| | Al or Cu wire (3) 2/0...400 MCM or 70...185 mm ² | | 140G-M-TLA33 | 140G-M-TLA34 |
| | Cu wire only (2) 3/0...350 MCM or 85...185 mm ² | | 140G-M-TLC23 | 140G-M-TLC24 |
|  <p><i>Representative Photo</i></p> | Cu wire only (3) 2/0...350 MCM or 70...185 mm ² | N, NS | 140G-M-TLC33 | 140G-M-TLC34 |
| | Al or Cu wire (4) 4/0...500 MCM or 70...240 mm ² | | 140G-N-TLA43 | 140G-N-TLA44 |
| | Cu wire only (4) 4/0...500 MCM or 70...240 mm ² | | 140G-N-TLC43 | 140G-N-TLC44 |
| | Al or Cu wire (6) 1/0...750 MCM or 50...400 mm ² | | 140G-R-TLA63 | — |
| <p><i>Representative Photo</i></p> | Cu wire only (6) 1/0...750 MCM or 50...400 mm ² | R | 140G-R-TLC63 | — |