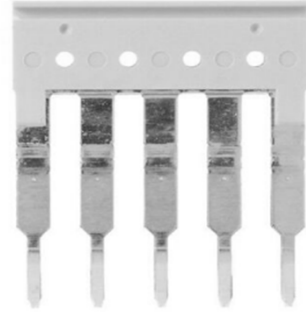


Product Details and Certifications

Cross Reference RA Part Number: 1492-CJL4-2 A

 **Product: 1492-CJL4-2**

Description: Plug-In Center Jumper, 4 mm Center to Center,
2 Poles, Gray



Representative Photo Only (actual product may vary based on configuration sections)

ACCESSORY SELECTION

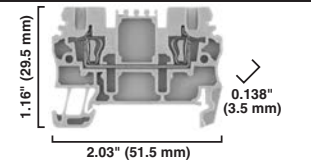
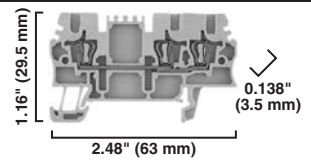
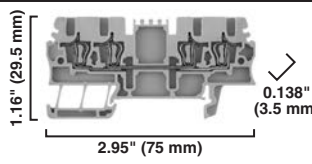
Bulletin Number	1492 IEC Terminal Block Accessories
Accessory Selection	Individual Accessory Selection

SELECTION

Screw Type Center Jumpers

Spring-Clamp Connection Terminal Blocks

Standard Feed-Through Blocks

	1492-L2				1492-L2T				1492-L2Q			
Dimensions are not intended to be used for manufacturing purposes. Note: Height dimension is measured from top of rail to top of terminal block.												
Specifications	<i>Feed-through terminal block</i>				<i>Feed-through terminal block with 2 connection points on one side</i>				<i>Feed-through terminal block with 2 connection points per side</i>			
Certifications		CSA	IEC	ATEX		CSA	IEC	ATEX		CSA	IEC	ATEX
Voltage Rating	300V AC/DC		500V AC/DC	550V AC/DC	300V AC/DC		500V AC/DC	550V AC/DC	300V AC/DC		500V AC/DC	550V AC/DC
Maximum Current	15 A	20 A	17.5 A	15 A	15 A	20 A	17.5 A	15 A	15 A	20 A	17.5 A	15 A
Wire Range (Rated Cross Section)	#26...14 AWG		1.5 mm ²	1.5 mm ²	#26...14 AWG		1.5 mm ²	1.5 mm ²	#26...14 AWG		1.5 mm ²	1.5 mm ²
Wire Strip Length	0.39 in. (10 mm)				0.39 in. (10 mm)				0.39 in. (10 mm)			
Density	87 pcs/ft (285 pcs/m)				87 pcs/ft (285 pcs/m)				87 pcs/ft (285 pcs/m)			
Housing Temperature Range	-58...+248 °F (-50...+120 °C)				-58...+248 °F (-50...+120 °C)				-58...+248 °F (-50...+120 °C)			
Terminal Blocks		Cat. No.		Pkg Qty.		Cat. No.		Pkg Qty.		Cat. No.		Pkg Qty.
Color	Grey	1492-L2		50		1492-L2T		50		1492-L2Q		50
	Red	1492-L2-RE		50		1492-L2T-RE		50		1492-L2Q-RE		50
	Blue	1492-L2-B		50		1492-L2T-B		50		1492-L2Q-B		50
	Black	1492-L2-BL		50		1492-L2T-BL		50		1492-L2Q-BL		50
	Green	1492-L2-G		50		1492-L2T-G		50		1492-L2Q-G		50
	Yellow	1492-L2-Y		50		1492-L2T-Y		50		1492-L2Q-Y		50
	Orange	1492-L2-OR		50		1492-L2T-OR		50		1492-L2Q-OR		50
	Brown	1492-L2-BR		50		1492-L2T-BR		50		1492-L2Q-BR		50
	White	1492-L2-W		50		1492-L2T-W		50		1492-L2Q-W		50
Accessories		Cat. No.		Pkg Qty.		Cat. No.		Pkg Qty.		Cat. No.		Pkg Qty.
Mounting Rails												
1 m Symmetrical DIN (Steel)		199-DR1		10		199-DR1		10		199-DR1		10
1 m Symmetrical DIN (Aluminum)		1492-DR5		10		1492-DR5		10		1492-DR5		10
1 m Hi-Rise Sym. DIN (Aluminum)		1492-DR6		2		1492-DR6		2		1492-DR6		2
1 m Angled Hi-Rise Sym. DIN (Steel)		1492-DR7		2		1492-DR7		2		1492-DR7		2
End Barriers	Grey	1492-EBL2		50		1492-EBL2T		50		1492-EBL2Q		50
	Blue	1492-EBL2-B		50		1492-EBL2T-B		50		1492-EBL2Q-B		50
	Yellow	1492-EBL2-Y		50		1492-EBL2T-Y		50		1492-EBL2Q-Y		50
End Anchors and Retainers												
Screwless End Retainer		1492-ERL35		20		1492-ERL35		20		1492-ERL35		20
DIN Rail — Normal Duty		1492-EAJ35		100		1492-EAJ35		100		1492-EAJ35		100
DIN Rail — Heavy Duty		1492-EAHJ35		50		1492-EAHJ35		50		1492-EAHJ35		50
Jumpers												
Plug-in Center Jumper — 10-Pole		1492-CJL4-10		20		1492-CJL4-10		20		1492-CJL4-10		20
Plug-in Center Jumper — 5-Pole		1492-CJL4-5		60		1492-CJL4-5		60		1492-CJL4-5		60
Plug-in Center Jumper — 4-Pole		1492-CJL4-4		60		1492-CJL4-4		60		1492-CJL4-4		60
Plug-in Center Jumper — 3-Pole		1492-CJL4-3		60		1492-CJL4-3		60		1492-CJL4-3		60
Plug-in Center Jumper — 2-Pole		1492-CJL4-2		60		1492-CJL4-2		60		1492-CJL4-2		60
Other Accessories												
Reducing Sleeves #28...#24 AWG (0.13...0.2 mm ²) White		1492-PSL2-2		100		1492-PSL2-2		100		1492-PSL2-2		100
Reducing Sleeves #22...#20 AWG (0.25...0.5 mm ²) Grey		1492-PSL2-5		100		1492-PSL2-5		100		1492-PSL2-5		100
Test Plug (Stackable)		1492-TPL4		25		1492-TPL4		25		1492-TPL4		25
Electrical Warning Plate		1492-EWPL4		20		1492-EWPL4		20		1492-EWPL4		20
Marking Systems												
Snap-In Marker Cards		1492-M3X12 (120/card)		5		1492-M3X12 (120/card)		5		1492-M3X12 (120/card)		5
Snap-In Marker Cards		1492-M3X5 (100/card)		5		1492-M3X5 (100/card)		5		1492-M3X5 (100/card)		5

