

Product Details and Certifications

Cross Reference RA Part Number: 1492-CJL7 A

 **Product: 1492-CJL7**

Description: Center Jumper Link, 7 mm Center to Center,
Gray, Pkg. Qty. of 10



Representative Photo Only (actual product may vary based on configuration sections)

ACCESSORY SELECTION

Bulletin Number	1492 IEC Terminal Block Accessories
Accessory Selection	Individual Accessory Selection

SELECTION

Screw Type Center Jumpers

Screw Connection Terminal Blocks


Space-Saver Feed-Through Blocks

1492-W3

1492-W4

1492-W6

Dimensions are not intended to be used for manufacturing purposes.
Note: Height dimension is measured from top of rail to top of terminal block.

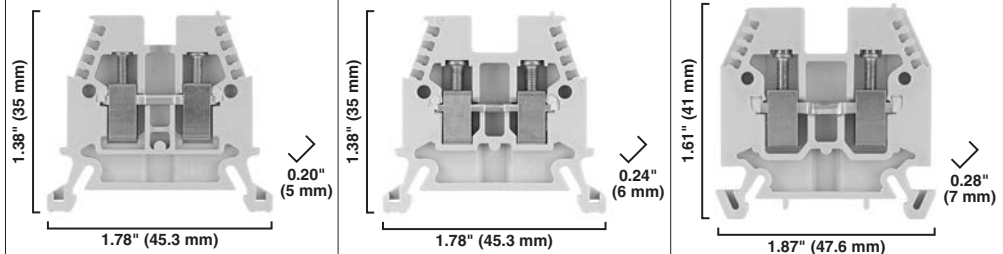

Specifications		Single-circuit terminal block.				Single-circuit terminal block.				Single-circuit terminal block.			
Certifications		UL	IEC	CSA	ATEX	UL	IEC	CSA	ATEX	UL	IEC	CSA	ATEX
Voltage Rating		600V AC/DC	800V AC/DC	600V AC/DC	550V AC/DC	600V AC/DC	800V AC/DC	600V AC/DC	550V AC/DC	600V AC/DC	800V AC/DC	600V AC/DC	550V AC/DC
Maximum Current		20 A	24 A	20 A	24 A	30 A	32 A	30 A	32 A	40 A	41 A	40 A	41 A
Wire Range (Rated Cross Section)		#30...14 AWG	0.5...2.5 mm ²	#22...14 AWG	2.5 mm ²	#22...10 AWG	0.5...4.0 mm ²	#22...10 AWG	4.0 mm ²	#22...10 AWG	0.5...6.0 mm ²	#22...10 AWG	6.0 mm ²
Wire Strip Length		0.39 in. (10 mm)				0.35 in. (9 mm)				0.47 in. (12 mm)			
Recommended Tightening Torque		5.0...5.6 lb•in (0.6 N•m)				5.0...5.6 lb•in (0.6 N•m)				5.6...6.8 lb•in (0.7 N•m)			
Density		61 pcs/ft (200 pcs/m)				50 pcs/ft (166 pcs/m)				43 pcs/ft (142 pcs/m)			
Housing Temperature Range		-40...+195 °F (-40...+90 °C)				-40...+195 °F (-40...+90 °C)				-40...+195 °F (-40...+90 °C)			
Terminal Blocks		Cat. No.		Pkg Qty.		Cat. No.		Pkg Qty.		Cat. No.		Pkg Qty.	
Color:	Grey	1492-W3		50		1492-W4		50		1492-W6		50	
	Red	1492-W3-RE		50		1492-W4-RE		50		1492-W6-RE		50	
	Blue	1492-W3-B		50		1492-W4-B		50		1492-W6-B		50	
	Black	1492-W3-BL		50		1492-W4-BL		50		1492-W6-BL		50	
	Green	1492-W3-G		50		1492-W4-G		50		1492-W6-G		50	
	Yellow	1492-W3-Y		50		1492-W4-Y		50		1492-W6-Y		50	
	Orange	1492-W3-OR		50		1492-W4-OR		50		1492-W6-OR		50	
	Brown	1492-W3-BR		50		1492-W4-BR		50		1492-W6-BR		50	
	White	1492-W3-W		50		1492-W4-W		50		1492-W6-W		50	
Accessories		Cat. No.		Pkg Qty.		Cat. No.		Pkg Qty.		Cat. No.		Pkg Qty.	
Mounting Rails:													
1 m Symmetrical DIN (Steel)		199-DR1		10		199-DR1		10		199-DR1		10	
1 m Symmetrical DIN (Aluminum)		1492-DR5		10		1492-DR5		10		1492-DR5		10	
1 m Hi-Rise Sym. DIN (Aluminum)		1492-DR6		2		1492-DR6		2		1492-DR6		2	
1 m Angled Hi-Rise Sym. DIN (Steel)		1492-DR7		2		1492-DR7		2		1492-DR7		2	
End Barrier		1492-EB3		50		1492-EB3		50		1492-EB10		50	
End Anchors and Retainers:													
Screwless End Retainer		1492-ERL35		20		1492-ERL35		20		1492-ERL35		20	
DIN Rail — Normal Duty		1492-EAJ35		100		1492-EAJ35		100		1492-EAJ35		100	
DIN Rail — Heavy Duty		1492-EAHJ35		50		1492-EAHJ35		50		1492-EAHJ35		50	
Jumpers:													
Insulated Side Jumper		1492-SJ5-10 (10-pole)		10		1492-N42 (2-pole)		50		—		—	
						1492-SJ6-10 (10-pole)		10					
Center Jumper — 50-pole		1492-CJ5-50		5		1492-CJ6-50		5		—		—	
Center Jumper — 40-pole		—		—		—		—		1492-CJ7-40		5	
Center Jumper — 10-pole		1492-CJ5-10		10		1492-CJ6-10		10		1492-CJ7-10		10	
Center Jumper — 5-pole		1492-CJ5-5		10		1492-CJ6-5		10		1492-CJ7-5		10	
Center Jumper — 4-pole		1492-CJ5-4		10		1492-CJ6-4		10		1492-CJ7-4		10	
Center Jumper — 3-pole		1492-CJ5-3		10		1492-CJ6-3		10		1492-CJ7-3		10	
Center Jumper — 2-pole		1492-CJ5-2		10		1492-CJ6-2		10		1492-CJ7-2		10	
Center Jumper Link		1492-CJL5		10		1492-CJL6		10		1492-CJL7		10	
Center Jumper Cover — White*		1492-CJCW5		20		1492-CJCW6		20		1492-CJCW6		20	
Other Accessories:													
Partition Plate		1492-PP3		50		1492-PP3		50		1492-PP10		50	
Separation Plate		1492-SP3		50		1492-SP3		50		—		—	
Test Plug		—		—		1492-TP28		10		1492-TP28		10	
Stackable Test Plug (with Legs)		—		—		1492-TP6EWL		10		—		—	
Stackable Test Plug (without Legs)		—		—		1492-TP6E		10		—		—	
Test Plug Adapter		1492-TA285		10		1492-TA40		10		1492-TA40		10	
Electrical Warning Plate (1-pole)		1492-EWP5		10		1492-EWP6		10		1492-EWP7		10	
Electrical Warning Plate (4-pole)		1492-EWP5-4		10		1492-EWP6-4		10		1492-EWP7-4		10	
Marking Systems:													
Snap-in Marker Cards		1492-MS5X12 (80/card)		5		1492-MS6X12 (80/card)		5		1492-MS6X12 (80/card)		5	

* May only be used as a marking surface. Cannot be installed over a center jumper.