

Product Details and Certifications

Cross Reference RA Part Number: 1492-EAJ15 A

 **Product: 1492-EAJ15**

Description: 1492 Terminal Block, End Anchor, Used w/ Mini
15mm Din Rail



Representative Photo Only (actual product may vary based on configuration sections)

ACCESSORY SELECTION


Bulletin Number	1492 Terminal Block Accessories
Accessory Selection	Individual Accessory Selection

SELECTION

1492 End Anchor Accessory

Screw Connection Terminal Blocks

Mini Blocks

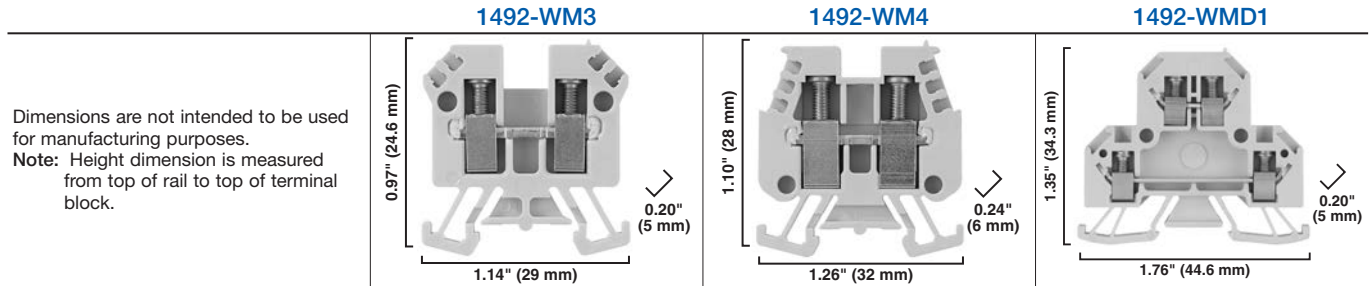

Dimensions are not intended to be used for manufacturing purposes.
Note: Height dimension is measured from top of rail to top of terminal block.

Specifications		Single-circuit mini terminal block.				Single-circuit mini terminal block.				Two-circuit mini terminal block.		
Certifications			IEC	CSA	ATEX		IEC	CSA	ATEX		CSA	IEC
Voltage Rating		300V AC/DC	500V AC/DC	300V AC/DC	420V AC/DC	300V AC/DC	500V AC/DC	300V AC/DC	420V AC/DC	300V AC/DC	300V AC/DC	500V AC/DC
Maximum Current		15 A	24 A	15 A	24 A	20 A	32 A	20 A	32 A	15 A	15 A	17.5 A
Wire Range (Rated Cross Section)		#30...14 AWG	0.5...2.5 mm ²	#22...14 AWG	2.5 mm ²	#22...12 AWG	0.5...4.0 mm ²	#22...12 AWG	4.0 mm ²	#22...16 AWG		0.5...1.5 mm ²
Wire Strip Length		0.24 in. (6 mm)				0.39 in. (10 mm)				0.35 in. (9 mm)		
Recommended Tightening Torque		4.2...4.6 lb•in (0.47...0.52 N•m)				4.7...6.2 lb•in (0.53...0.70 N•m)				4.2...4.6 lb•in (0.47...0.52 N•m)		
Density		61 pcs/ft (200/m)				50 pcs/ft (166/m)				61 pcs/ft (200/m)		
Housing Temperature Range		-40...+195 °F (-40...+90 °C)				-40...+195 °F (-40...+90 °C)				-40...+195 °F (-40...+90 °C)		
Terminal Blocks		Cat. No.		Pkg Qty.	Cat. No.		Pkg Qty.	Cat. No.		Pkg Qty.		
Color:	Grey	1492-WM3		50	1492-WM4		50	1492-WMD1		50		
	Red	1492-WM3-RE		50	1492-WM4-RE		50	1492-WMD1-RE		50		
	Blue	1492-WM3-B		50	1492-WM4-B		50	1492-WMD1-B		50		
	Black	1492-WM3-BL		50	1492-WM4-BL		50	1492-WMD1-BL		50		
	Green	1492-WM3-G		50	1492-WM4-G		50	1492-WMD1-G		50		
	Yellow	1492-WM3-Y		50	1492-WM4-Y		50	1492-WMD1-Y		50		
	Orange	1492-WM3-OR		50	1492-WM4-OR		50	1492-WMD1-OR		50		
	Brown	1492-WM3-BR		50	1492-WM4-BR		50	1492-WMD1-BR		50		
	White	1492-WM3-W		50	1492-WM4-W		50	1492-WMD1-W		50		
Accessories		Cat. No.		Pkg Qty.	Cat. No.		Pkg Qty.	Cat. No.		Pkg Qty.		
Mounting Rails: 1 m Sym. mini DIN (Steel)		1492-DR3		5	1492-DR3		5	1492-DR3		5		
End Barrier		1492-EBM3		50	1492-EBM4		50	1492-EBMD1		50		
End Anchors and Retainers: Mini Screwless End Retainer		1492-ERL15		20	1492-ERL15		20	1492-ERL15		20		
Mini DIN Anchor — Normal Duty		1492-EAJ15		50	1492-EAJ15		50	1492-EAJ15		50		
Jumpers: Insulated Side Jumper		1492-SJM5-10 (10-pole)		10	1492-N42 (2-pole) 1492-SJ6-10 (10-pole)		50 10	—		—		
Side Jumper — 12-pole uninsulated		—		—	—		—	1492-SJMD5-12 (Uninsulated)		10		
Center Jumper — 50-pole		—		—	1492-CJD6-50		5	—		—		
Center Jumper — 10-pole		1492-CJM5-10		10	1492-CJD6-10		10	—		—		
Center Jumper — 5-pole		—		—	1492-CJD6-5		10	—		—		
Center Jumper — 4-pole		—		—	1492-CJD6-4		10	—		—		
Center Jumper — 3-pole		1492-CJM5-3		10	1492-CJD6-3		10	—		—		
Center Jumper — 2-pole		1492-CJM5-2		10	1492-CJD6-2		10	—		—		
Center Jumper Link		1492-CJL5		10	1492-CJL6		10	—		—		
Other Accessories: Partition Plate		1492-PPM3		50	1492-PPM3		50	1492-PPMD1		50		
Test Plug		—		—	1492-TP28		10	—		—		
Test Plug Adapter		1492-TA285		10	1492-TA40		10	—		—		
Electrical Warning Plate (4-pole)		—		—	1492-EWP6-4		10	—		—		
Marking Systems: Snap-in Marker Card		1492-MS5X5 (80/card)		5	1492-MS6X9 (80/card)		5	1492-MS5X5 (80/card)		5		

