

# Product Details and Certifications

**Cross Reference RA Part Number: 1492-EBL4T-Y A**

 **Product: 1492-EBL4T-Y**

Description: 1492 Terminal Block, End Barrier, Yellow (Standard), Qty. 50



Representative Photo Only (actual product may vary based on configuration sections)

## ***ACCESSORY SELECTION***

---

Bulletin Number	1492 Terminal Block Accessories
Accessory Selection	Individual Accessory Selection

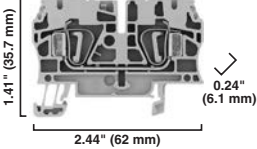
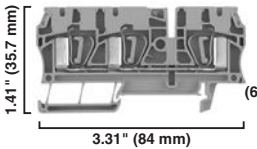
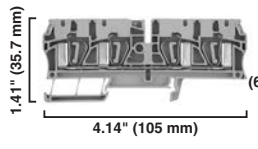
## ***SELECTION***

---

1492 Accessory

# Spring-Clamp Connection Terminal Blocks

## Standard Feed-Through Blocks

	1492-L4				1492-L4T				1492-L4Q			
Dimensions are not intended to be used for manufacturing purposes. Note: Height dimension is measured from top of rail to top of terminal block.												
<b>Specifications</b>	<i>Feed-through terminal block</i>				<i>Feed-through terminal block with 3 connection points, 2 on one side</i>				<i>Feed-through terminal block with 2 connection points on each side</i>			
<b>Certifications</b>												
<b>Voltage Rating</b>	600V AC/DC		800V AC/DC	550V AC/DC	600V AC/DC		800V AC/DC	550V AC/DC	600V AC/DC		800V AC/DC	550V AC/DC
<b>Maximum Current</b>	33 A	35 A	32 A	28 A	33 A	35 A	32 A	28 A	33 A	35 A	32 A	28 A
<b>Wire Range (Rated Cross Section)</b>	#26...10 AWG		4 mm <sup>2</sup>	4 mm <sup>2</sup> (20...10 AWG)	#26...10 AWG		4 mm <sup>2</sup>	4 mm <sup>2</sup> (20...10 AWG)	#26...10 AWG		4 mm <sup>2</sup>	4 mm <sup>2</sup> (20...10 AWG)
<b>Wire Strip Length</b>	0.47 in. (12 mm)				0.47 in. (12 mm)				0.47 in. (12 mm)			
<b>Density</b>	49 pcs/ft (163 pcs/m)				49 pcs/ft (163 pcs/m)				49 pcs/ft (163 pcs/m)			
<b>Housing Temperature Range</b>	-58...+248 °F (-50...+120 °C)				-58...+248 °F (-50...+120 °C)				-58...+248 °F (-50...+120 °C)			
<b>Short-Circuit Current Rating</b>	See page 12-78											
<b>Terminal Blocks</b>		<b>Cat. No.</b>	<b>Pkg Qty.</b>		<b>Cat. No.</b>	<b>Pkg Qty.</b>		<b>Cat. No.</b>	<b>Pkg Qty.</b>		<b>Cat. No.</b>	<b>Pkg Qty.</b>
<b>Color</b>	Grey	<b>1492-L4</b>	50		<b>1492-L4T</b>	50		<b>1492-L4Q</b>	50		<b>1492-L4Q-RE</b>	50
	Red	<b>1492-L4-RE</b>	50		<b>1492-L4T-RE</b>	50		<b>1492-L4Q-RE</b>	50		<b>1492-L4Q-B</b>	50
	Blue	<b>1492-L4-B</b>	50		<b>1492-L4T-B</b>	50		<b>1492-L4Q-B</b>	50		<b>1492-L4Q-BL</b>	50
	Black	<b>1492-L4-BL</b>	50		<b>1492-L4T-BL</b>	50		<b>1492-L4Q-BL</b>	50		<b>1492-L4Q-G</b>	50
	Green	<b>1492-L4-G</b>	50		<b>1492-L4T-G</b>	50		<b>1492-L4Q-G</b>	50		<b>1492-L4Q-Y</b>	50
	Yellow	<b>1492-L4-Y</b>	50		<b>1492-L4T-Y</b>	50		<b>1492-L4Q-Y</b>	50		<b>1492-L4Q-OR</b>	50
	Orange	<b>1492-L4-OR</b>	50		<b>1492-L4T-OR</b>	50		<b>1492-L4Q-OR</b>	50		<b>1492-L4Q-BR</b>	50
	Brown	<b>1492-L4-BR</b>	50		<b>1492-L4T-BR</b>	50		<b>1492-L4Q-BR</b>	50		<b>1492-L4Q-W</b>	50
	White	<b>1492-L4-W</b>	50		<b>1492-L4T-W</b>	50		<b>1492-L4Q-W</b>	50			
<b>Accessories</b>		<b>Cat. No.</b>	<b>Pkg Qty.</b>		<b>Cat. No.</b>	<b>Pkg Qty.</b>		<b>Cat. No.</b>	<b>Pkg Qty.</b>		<b>Cat. No.</b>	<b>Pkg Qty.</b>
<b>Mounting Rails</b>												
1 m Symmetrical DIN (Steel)		<b>199-DR1</b>	10		<b>199-DR1</b>	10		<b>199-DR1</b>	10		<b>199-DR1</b>	10
1 m Symmetrical DIN (Aluminum)		<b>1492-DR5</b>	10		<b>1492-DR5</b>	10		<b>1492-DR5</b>	10		<b>1492-DR5</b>	10
1 m Hi-Rise Sym. DIN (Aluminum)		<b>1492-DR6</b>	2		<b>1492-DR6</b>	2		<b>1492-DR6</b>	2		<b>1492-DR6</b>	2
1 m Angled Hi-Rise Sym. DIN (Steel)		<b>1492-DR7</b>	2		<b>1492-DR7</b>	2		<b>1492-DR7</b>	2		<b>1492-DR7</b>	2
<b>End Barriers</b>	Grey	<b>1492-EBL4</b>	50		<b>1492-EBL4T</b>	50		<b>1492-EBL4Q</b>	50		<b>1492-EBL4Q-B</b>	50
	Blue	<b>1492-EBL4-B</b>	50		<b>1492-EBL4T-B</b>	50		<b>1492-EBL4Q-B</b>	50		<b>1492-EBL4Q-Y</b>	50
	Yellow	<b>1492-EBL4-Y</b>	50		<b>1492-EBL4T-Y</b>	50		<b>1492-EBL4Q-Y</b>	50			
<b>End Anchors and Retainers</b>												
Screwless End Retainer		<b>1492-ERL35</b>	20		<b>1492-ERL35</b>	20		<b>1492-ERL35</b>	20		<b>1492-ERL35</b>	20
<b>DIN Rail — Normal Duty</b>		<b>1492-EAJ35</b>	100		<b>1492-EAJ35</b>	100		<b>1492-EAJ35</b>	100		<b>1492-EAJ35</b>	100
<b>DIN Rail — Heavy Duty</b>		<b>1492-EAHJ35</b>	50		<b>1492-EAHJ35</b>	50		<b>1492-EAHJ35</b>	50		<b>1492-EAHJ35</b>	50
<b>Jumpers:</b>												
Plug-in Center Jumper — 10-Pole		<b>1492-CJK6-10</b>	20		<b>1492-CJK6-10</b>	20		<b>1492-CJK6-10</b>	20		<b>1492-CJK6-10</b>	20
Plug-in Center Jumper — 9-Pole		<b>1492-CJK6-9</b>	20		<b>1492-CJK6-9</b>	20		<b>1492-CJK6-9</b>	20		<b>1492-CJK6-9</b>	20
Plug-in Center Jumper — 8-Pole		<b>1492-CJK6-8</b>	20		<b>1492-CJK6-8</b>	20		<b>1492-CJK6-8</b>	20		<b>1492-CJK6-8</b>	20
Plug-in Center Jumper — 7-Pole		<b>1492-CJK6-7</b>	20		<b>1492-CJK6-7</b>	20		<b>1492-CJK6-7</b>	20		<b>1492-CJK6-7</b>	20
Plug-in Center Jumper — 6-Pole		<b>1492-CJK6-6</b>	20		<b>1492-CJK6-6</b>	20		<b>1492-CJK6-6</b>	20		<b>1492-CJK6-6</b>	20
Plug-in Center Jumper — 5-Pole		<b>1492-CJK6-5</b>	20		<b>1492-CJK6-5</b>	20		<b>1492-CJK6-5</b>	20		<b>1492-CJK6-5</b>	20
Plug-in Center Jumper — 4-Pole		<b>1492-CJK6-4</b>	60		<b>1492-CJK6-4</b>	60		<b>1492-CJK6-4</b>	60		<b>1492-CJK6-4</b>	60
Plug-in Center Jumper — 3-Pole		<b>1492-CJK6-3</b>	60		<b>1492-CJK6-3</b>	60		<b>1492-CJK6-3</b>	60		<b>1492-CJK6-3</b>	60
Plug-in Center Jumper — 2-Pole		<b>1492-CJK6-2</b>	60		<b>1492-CJK6-2</b>	60		<b>1492-CJK6-2</b>	60		<b>1492-CJK6-2</b>	60
<b>Other Accessories</b>												
Reducing Sleeves #26...#24 AWG (0.13...0.2 mm <sup>2</sup> ) White		<b>1492-PSL4-2</b>	100		<b>1492-PSL4-2</b>	100		<b>1492-PSL4-2</b>	100		<b>1492-PSL4-2</b>	100
Reducing Sleeves #20...#22 AWG (0.25...0.5 mm <sup>2</sup> ) Grey		<b>1492-PSL4-5</b>	100		<b>1492-PSL4-5</b>	100		<b>1492-PSL4-5</b>	100		<b>1492-PSL4-5</b>	100
Reducing Sleeves #18 AWG (0.75...1.0 mm <sup>2</sup> ) Dark Grey		<b>1492-PSL4-10</b>	100		<b>1492-PSL4-10</b>	100		<b>1492-PSL4-10</b>	100		<b>1492-PSL4-10</b>	100
<b>Test Plug</b>		<b>1492-TP23</b>	20		<b>1492-TP23</b>	20		<b>1492-TP23</b>	20		<b>1492-TP23</b>	20
Test Plug (Stackable)		<b>1492-TPL6</b>	25		<b>1492-TPL6</b>	25		<b>1492-TPL6</b>	25		<b>1492-TPL6</b>	25
Electrical Warning Plate		<b>1492-EWPL6</b>	20		<b>1492-EWPL6</b>	20		<b>1492-EWPL6</b>	20		<b>1492-EWPL6</b>	20
<b>Marking Systems</b>												
Snap-In Marker Cards		<b>1492-M6X10</b> (120/card)	5		<b>1492-M6X10</b> (120/card)	5		<b>1492-M6X10</b> (120/card)	5		<b>1492-M6X10</b> (120/card)	5
Snap-In Marker Cards		<b>1492-M6X5</b> (200/card)	5		<b>1492-M6X5</b> (200/card)	5		<b>1492-M6X5</b> (200/card)	5		<b>1492-M6X5</b> (200/card)	5
Hinged Marker Cards		<b>1492-MH6X12</b> (80/card)	5		<b>1492-MH6X12</b> (80/card)	5		<b>1492-MH6X12</b> (80/card)	5		<b>1492-MH6X12</b> (80/card)	5

