


Product Details and Certifications

Cross Reference RA Part Number: 1492-LC3 A

Product: 1492-LC3

Description: 1492-L Spring Clamp Terminal Block, One-Circuit Feed-Through with plug in comb connections on one side, 2.5mm² (# 22 AWG - # 14 AWG) Standard Feedthrough, Gray (Standard)

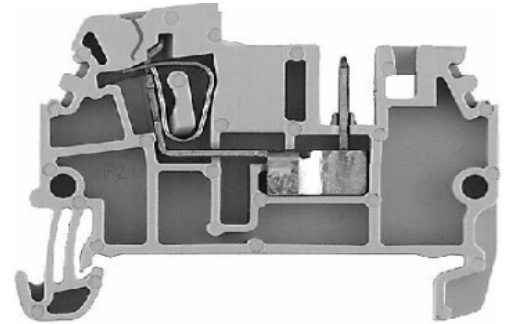

Representative Photo Only (actual product may vary based on configuration sections)

BLOCK STYLE

Bulletin Number	1492 Terminal Block Accessories
Base Block Style	Plug-In Connection Blocks

BASE DATA

Base Block Type	One-Circuit Feed-Through with plug in comb connections on one side
-----------------	--

DETAIL DATA

Features	Standard Feedthrough
Maximum Wire Size & Rating	UL: 26-12 AWG (10A @300V AC/DC)\ nCSA: 26-12 AWG (10A @300V AC/DC)\nIEC: 2.5mm ² (16A @250V AC/DC)
Color	Gray (Standard)

CERTIFICATIONS AND APPROVALS


UR	UL 486E, UL 1059; Reference File: E40735
CSA	CSA C22.2 No. 65, No. 158; On Website, Name: Rockwell, Keyword Search: 1492
IEC	EN 60947-1, EN 60947-7-1(Feed-Through), -2(Ground), -3(Fuse)
Short Circuit Current Rating	This terminal block carries a minimum of 10kA SCCR rating for all protection methods. Please see the table for other possible elevated ratings.
For CSA Certifications:	http://directories.csa-international.org/directorymain.asp
For UL Certifications Directory:	http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm

Spring-Clamp Connection Terminal Blocks


Plug-in Connection Blocks



1492-LC3

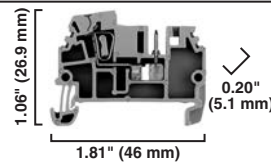

1492-LDC3

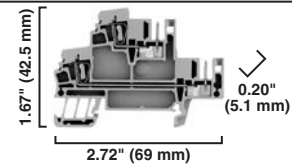

Dimensions are not intended to be used for manufacturing purposes.
Note: Height dimension is measured from top of rail to top of terminal block.

Specifications	1492-LC3			1492-LDC3		
	<i>Feed-through terminal block with plug in comb connection on one side.</i>			<i>Two Circuit terminal block with plug in comb connection on one side of each circuit</i>		
Certifications	UL	CSA	IEC	UL	CSA	IEC
Voltage Rating	300V AC/DC		250V AC/DC	300V AC/DC		250V AC/DC
Maximum Current	10 A		16 A	10 A		16 A
Wire Range (Rated Cross Section)	#26...12 AWG		2.5 mm ²	#26...14 AWG		2.5 mm ²
Wire Strip Length	0.39 in. (10 mm)			0.39 in. (10 mm)		
Density	59 pcs/ft (196 pcs/m)			59 pcs/ft (196 pcs/m)		
Housing Temperature Range	-58...+248 °F (-50...+120 °C)			-58...+248 °F (-50...+120 °C)		



Terminal Blocks	Cat. No.	Pkg Qty.	Cat. No.	Pkg Qty.
Color	Grey	1492-LC3	1492-LDC3	50
Plug Connection Strips	Cat. No.	Pkg Qty.	Cat. No.	Pkg Qty.
Color/Quantity	Black/2-Pole	1492-QP5-2	1492-QP5-2	100
	Black/3-Pole	1492-QP5-3	1492-QP5-3	100
	Black/4-Pole	1492-QP5-4	1492-QP5-4	100
	Black/5-Pole	1492-QP5-5	1492-QP5-5	50
	Black/6-Pole	1492-QP5-6	1492-QP5-6	50
	Black/7-Pole	1492-QP5-7	1492-QP5-7	50
	Black/8-Pole	1492-QP5-8	1492-QP5-8	50
	Black/9-Pole	1492-QP5-9	1492-QP5-9	50
	Black/10-Pole	1492-QP5-10	1492-QP5-10	50
	Black/11-Pole	1492-QP5-11	1492-QP5-11	50
	Black/12-Pole	1492-QP5-12	1492-QP5-12	50
Accessories	Cat. No.	Pkg Qty.	Cat. No.	Pkg Qty.
Mounting Rails				
1 m Symmetrical DIN (Steel)	199-DR1	10	199-DR1	10
1 m Symmetrical DIN (Aluminum)	1492-DR5	10	1492-DR5	10
1 m Hi-Rise Sym. DIN (Aluminum)	1492-DR6	2	1492-DR6	2
1 m Angled Hi-Rise Sym. DIN (Steel)	1492-DR7	2	1492-DR7	2
End Barriers	Grey	1492-EBLC3	1492-EBLDC3	20
End Anchors and Retainers:				
Screwless End Retainer	1492-ERL35	20	1492-ERL35	20
DIN Rail — Normal Duty	1492-EAJ35	100	1492-EAJ35	100
DIN Rail — Heavy Duty	1492-EAHJ35	50	1492-EAHJ35	50
Jumpers				
Plug-in Center Jumper — 50-Pole	1492-CJLJ5-50	10	1492-CJLJ5-50	10
Plug-in Center Jumper — 10-Pole	1492-CJLJ5-10	20	1492-CJLJ5-10	20
Plug-in Center Jumper — 9-Pole	1492-CJLJ5-9	20	1492-CJLJ5-9	20
Plug-in Center Jumper — 8-Pole	1492-CJLJ5-8	20	1492-CJLJ5-8	20
Plug-in Center Jumper — 7-Pole	1492-CJLJ5-7	20	1492-CJLJ5-7	20
Plug-in Center Jumper — 6-Pole	1492-CJLJ5-6	20	1492-CJLJ5-6	20
Plug-in Center Jumper — 5-Pole	1492-CJLJ5-5	20	1492-CJLJ5-5	20
Plug-in Center Jumper — 4-Pole	1492-CJLJ5-4	60	1492-CJLJ5-4	60
Plug-in Center Jumper — 3-Pole	1492-CJLJ5-3	60	1492-CJLJ5-3	60
Plug-in Center Jumper — 2-Pole	1492-CJLJ5-2	60	1492-CJLJ5-2	60
Other Accessories				
Group Marking Carrier	1492-GM35	25	1492-GM35	25
Marking Systems				
Snap-In Marker Cards	1492-M5X10 (144/card)	5	1492-M5X10 (144/card)	5
Snap-In Marker Cards	1492-M5X5 (200/card)	5	1492-M5X5 (200/card)	5
Hinged Marker Card	1492-MH5X10 (96/card)	5	—	—