
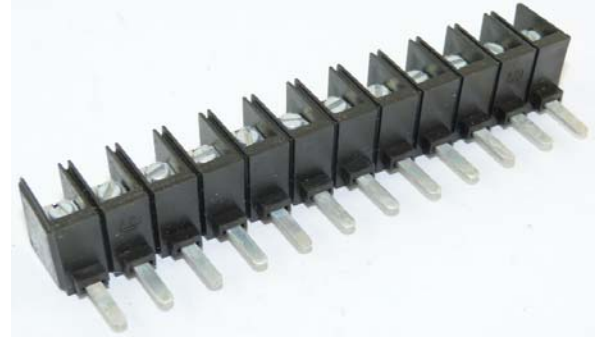


Product Details and Certifications

Cross Reference RA Part Number: 1492-N20 A

 **Product: 1492-N20**

Description: 1492 Terminal Block Accessories, Fanning Strip,
20 mm Center to Center, 12 Pole, None



Representative Photo Only (actual product may vary based on configuration sections)

ACCESSORY SELECTION

| | |
|---------------------|---------------------------------|
| Bulletin Number | 1492 Terminal Block Accessories |
| Accessory Selection | Individual Accessory Selection |

SELECTION

1492 Terminal Blocks and Wiring System

| | 1492-F8 | | 1492-CA1 | | 1492-CA1L | | |
|--|---|---------------------------------|--|----------------------------------|--|-----------------------------------|----|
| Dimensions are not intended to be used for manufacturing purposes. Note: Height dimension is measured from top of rail to top of terminal block. | | | | | | | |
| | Terminal block, screw terminal with wire clamp. | | Terminal block, tubular screw with pressure plate. | | Terminal block, screw with large head, pressure plate. | | |
| Specifications | | | | | | | |
| Certifications | UL/CSA | | UL/CSA | | UL/CSA | | |
| Voltage Rating | 300V AC/DC | | 600V AC/DC | | 600V AC/DC | | |
| Maximum Current | 25 A | | 55 A | | 55 A | | |
| Wire Range (Rated Cross Section) | #22...#14 AWG (0.5...2.5 mm ²) | | #22...#8 AWG (0.5...10 mm ²) | | #22...#8 AWG (0.5...10 mm ²) | | |
| Wire Strip Length | 0.25 in. (6.4 mm) | | 0.38 in. (9.7 mm) | | 0.38 in. (9.7 mm) | | |
| Recommended Tightening Torque | 6...14 lb•in (0.7...1.6 N•m) | | 8...16 lb•in (0.9...1.8 N•m) | | 8...16 lb•in (0.9...1.8 N•m) | | |
| Density | 30 pcs/ft (98 pcs/m) | | 30 pcs/ft (98 pcs/m) | | 30 pcs/ft (98 pcs/m) | | |
| Insulation Temperature Range | -40...+221 °F (-40...+105 °C) | | -40...+221 °F (-40...+105 °C) | | -40...+221 °F (-40...+105 °C) | | |
| Terminal Blocks | Cat. No. | Pkg Qty. | Cat. No. | Pkg Qty. | Cat. No. | Pkg Qty. | |
| Color: | White | 1492-F8 | 50 | 1492-CA1 | 50 | 1492-CA1L | 50 |
| | Two 3 ft Rails White | 1492-F8175 (88 pcs/rail) | 1 | 1492-CA1175 (88 pcs/rail) | 1 | 1492-CA1L175 (88 pcs/rail) | 1 |
| | Red | 1492-F8RE | 50 | 1492-CA1RE | 50 | 1492-CA1LRE | 50 |
| | Blue | 1492-F8B | 50 | 1492-CA1B | 50 | 1492-CA1LB | 50 |
| | Black | 1492-F8BL | 50 | 1492-CA1BL | 50 | 1492-CA1LBL | 50 |
| | Green | 1492-F8G | 50 | 1492-CA1G | 50 | 1492-CA1LG | 50 |
| | Yellow | 1492-F8Y | 50 | 1492-CA1Y | 50 | 1492-CA1LY | 50 |
| | Brown | 1492-F8BR | 50 | 1492-CA1BR | 50 | 1492-CA1LBR | 50 |
| | Violet | 1492-F8VT | 50 | 1492-CA1VT | 50 | 1492-CA1LVT | 50 |
| | Grey | 1492-F8GY | 50 | 1492-CA1GY | 50 | 1492-CA1LGY | 50 |
| | Orange | 1492-F1OR | 50 | 1492-CA1OR | 50 | 1492-CA1LOR | 50 |
| Accessories (page 12-109) | Cat. No. | Pkg Qty. | Cat. No. | Pkg Qty. | Cat. No. | Pkg Qty. | |
| Mounting Rails: | | | | | | | |
| A-B Rail | 1492-N1 | 20 | 1492-N1 | 20 | 1492-N1 | 20 | |
| 3 ft Rigid A-B Rail | 1492-N22 | 20 | 1492-N22 | 20 | 1492-N22 | 20 | |
| 3 ft High-Rise A-B Rail | 1492-N44 | 2 | 1492-N44 | 2 | 1492-N44 | 2 | |
| Standoff Brackets (use every 12 in.) | 1492-N25 | 2 | 1492-N25 | 2 | 1492-N25 | 2 | |
| End Barrier | 1492-N18 | 50 | 1492-N16 | 50 | 1492-N16 | 50 | |
| End Anchors: | | | | | | | |
| A-B Rail | 1492-N23 | 10 | 1492-N23 | 10 | 1492-N23 | 10 | |
| A-B Rail — Normal Duty | — | — | 1492-N47 | 50 | 1492-N47 | 50 | |
| A-B Rail — Retaining Clip — Light Duty | 1492-N2 | 50 | 1492-N2 | 50 | 1492-N2 | 50 | |
| Jumpers: | | | | | | | |
| 2-pole Uninsulated | 1492-N14 | 50 | 1492-N3 | 50 | 1492-N3 | 50 | |
| 50-pole Uninsulated | — | — | 1492-N30 | 50 | 1492-N30 | 50 | |
| Fanning Strip (12-pole can cut to desired length) | — | — | 1492-N20 | 1 | 1492-N20 | 1 | |
| Marking Systems | * | 1492-N5 | 1 | 1492-N45 | 20 | 1492-N45 | 20 |

* 1 sheet, 20 strips.