


Product Details and Certifications

Cross Reference RA Part Number: 1492-N30 A

 **Product: 1492-N30**

Description: 1492 Terminal Block Accessories, Uninsulated Side Jumper,
30 mm Center to Center, 50 Pole, None

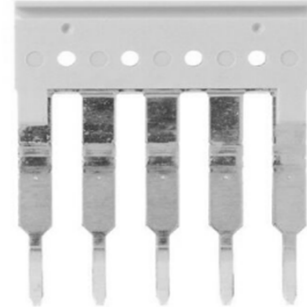

Representative Photo Only (actual product may vary based on configuration sections)

ACCESSORY SELECTION

Bulletin Number	1492 Terminal Block Accessories
Accessory Selection	Individual Accessory Selection

SELECTION

1492 Terminal Blocks and Wiring System

	1492-F8			1492-CA1		1492-CA1L	
Dimensions are not intended to be used for manufacturing purposes. Note: Height dimension is measured from top of rail to top of terminal block.							
	Terminal block, screw terminal with wire clamp.			Terminal block, tubular screw with pressure plate.		Terminal block, screw with large head, pressure plate.	
	UL/CSA			UL/CSA		UL/CSA	
	300V AC/DC			600V AC/DC		600V AC/DC	
Specifications							
Certifications							
Voltage Rating							
Maximum Current	25 A			55 A		55 A	
Wire Range (Rated Cross Section)	#22...#14 AWG (0.5...2.5 mm ²)			#22...#8 AWG (0.5...10 mm ²)		#22...#8 AWG (0.5...10 mm ²)	
Wire Strip Length	0.25 in. (6.4 mm)			0.38 in. (9.7 mm)		0.38 in. (9.7 mm)	
Recommended Tightening Torque	6...14 lb•in (0.7...1.6 N•m)			8...16 lb•in (0.9...1.8 N•m)		8...16 lb•in (0.9...1.8 N•m)	
Density	30 pcs/ft (98 pcs/m)			30 pcs/ft (98 pcs/m)		30 pcs/ft (98 pcs/m)	
Insulation Temperature Range	-40...+221 °F (-40...+105 °C)			-40...+221 °F (-40...+105 °C)		-40...+221 °F (-40...+105 °C)	
Terminal Blocks	Cat. No.	Pkg Qty.	Cat. No.	Pkg Qty.	Cat. No.	Pkg Qty.	
Color:	White	1492-F8	50	1492-CA1	50	1492-CA1L	50
	Two 3 ft Rails White	1492-F8175 (88 pcs/rail)	1	1492-CA1175 (88 pcs/rail)	1	1492-CA1L175 (88 pcs/rail)	1
	Red	1492-F8RE	50	1492-CA1RE	50	1492-CA1LRE	50
	Blue	1492-F8B	50	1492-CA1B	50	1492-CA1LB	50
	Black	1492-F8BL	50	1492-CA1BL	50	1492-CA1LBL	50
	Green	1492-F8G	50	1492-CA1G	50	1492-CA1LG	50
	Yellow	1492-F8Y	50	1492-CA1Y	50	1492-CA1LY	50
	Brown	1492-F8BR	50	1492-CA1BR	50	1492-CA1LBR	50
	Violet	1492-F8VT	50	1492-CA1VT	50	1492-CA1LVT	50
	Grey	1492-F8GY	50	1492-CA1GY	50	1492-CA1LGY	50
	Orange	1492-F1OR	50	1492-CA1OR	50	1492-CA1LOR	50
Accessories (page 12-109)	Cat. No.	Pkg Qty.	Cat. No.	Pkg Qty.	Cat. No.	Pkg Qty.	
Mounting Rails:							
A-B Rail	1492-N1	20	1492-N1	20	1492-N1	20	
3 ft Rigid A-B Rail	1492-N22	20	1492-N22	20	1492-N22	20	
3 ft High-Rise A-B Rail	1492-N44	2	1492-N44	2	1492-N44	2	
Standoff Brackets (use every 12 in.)	1492-N25	2	1492-N25	2	1492-N25	2	
End Barrier	1492-N18	50	1492-N16	50	1492-N16	50	
End Anchors:							
A-B Rail	1492-N23	10	1492-N23	10	1492-N23	10	
A-B Rail — Normal Duty	—	—	1492-N47	50	1492-N47	50	
A-B Rail — Retaining Clip — Light Duty	1492-N2	50	1492-N2	50	1492-N2	50	
Jumpers:							
2-pole Uninsulated	1492-N14	50	1492-N3	50	1492-N3	50	
50-pole Uninsulated	—	—	1492-N30	50	1492-N30	50	
Fanning Strip (12-pole can cut to desired length)	—	—	1492-N20	1	1492-N20	1	
Marking Systems	*	1492-N5	1	1492-N45	20	1492-N45	20

* 1 sheet, 20 strips.