


Product Details and Certifications

Cross Reference RA Part Number: PN-52371



Product: **1585D-D4TBJM-1**

Description: 1585 EtherNet Cable, 4 Conductors, M12, Female Front Mount Receptacle, Standard, RJ45, Straight Male, Teal RoboticTPE, 100BASE-Xt, 100 Mbit/s, Teal TPE, Flex Rated

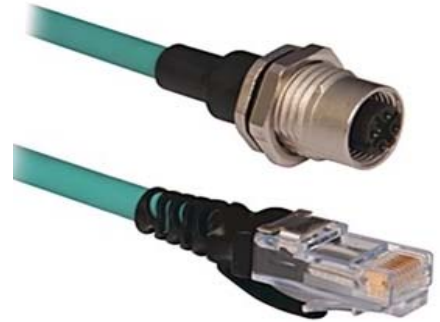

Representative Photo Only (actual product may vary based on configuration sections)

FIRST CONNECTOR TYPE

Connector Type	M12
First Connector Orientation	Female Front Mount Receptacle
Number of Conductors	4 Conductors

SECOND CONNECTOR TYPE

Second Connector Type	RJ45
Second Connector Orientation	Straight Male

CABLE DATA

Cable Type	Teal Robotic TPE
Cable Bandwidth	100BASE-TX, 100 Mbit/s
Connector Feature	Standard
Crossover	No

CORD LENGTH DATA

Standard or Build-to-Order Cable Length	Build-to-Order Cable Length
Cable Length	1 Meters

NOTES

First Connector Pinout:	Pinout:
Second Connector Pinout:	Flying Lead Color Codes:
Cable Rating	4 Conductor, Teal TPE, Flex Rated