


Product Details

Product: 194R-NA200P3

Description: IEC Disconnect, BS88 Fused, 32A, Open Style

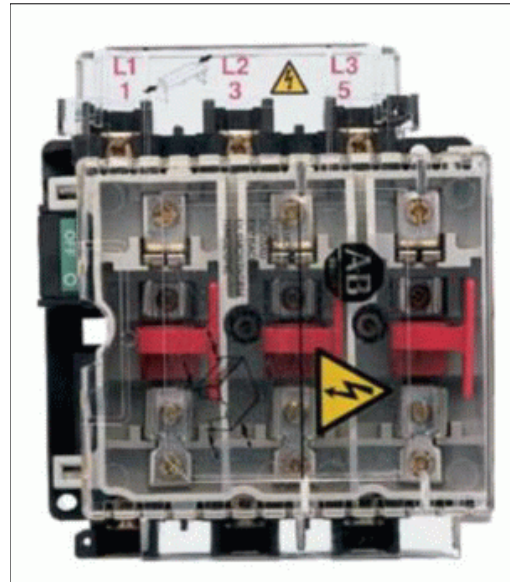

SYSTEM VOLTAGE DATA

Phases 3 Phase

SWITCH DATA

Fusing Type BS88
Enclosure Open
Link Type With Fuse Links
Switch Ampere Rating 32A

OPTION DATA

Kit No

LOAD DATA - Optional

Minimum Required HP 0 HP
Minimum Required kW 0 kW
Load FLA (Nameplate Value) 0 A

Certifications and Approvals

UL 508
CSA C22.2 No. 14
IEC 947-3 Low Voltage Switchgear and Controlgear part 3
CE
CSA CSA22.2 No. 4
IEC 947-3/ EN60947-3 Low Voltage Switchgear and Controlgear part 3
BS EN60947-3
VDE0660
NEMA KS-1 UL 1087/489
ASTA Certified
LOVAG Certified
UL 98