


Product Details

Product: 194R-NN060P3

Description: IEC Disconnect, UL/CSA Non-Fused,
60A, Open Style

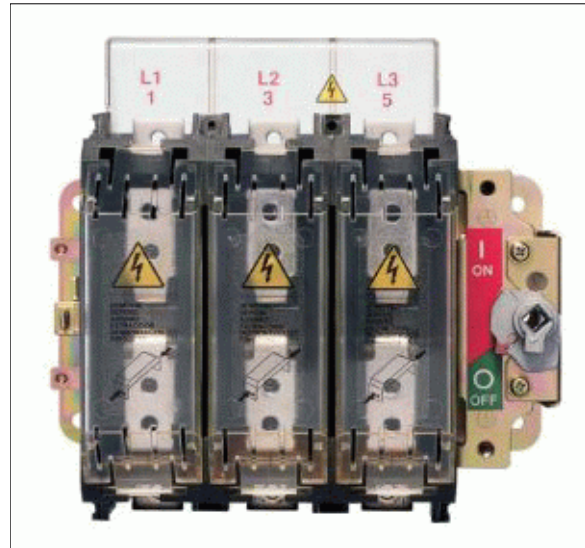

SWITCH DATA

Fusing Type	UL/CSA Non-Fused
Enclosure	Open
Switch Ampere Rating	60A
Fuse Class	Non-Fused

OPTION DATA

Kit	No
-----	----

LOAD DATA - Optional

Minimum Required HP	0 HP
Minimum Required kW	0 kW
Load FLA (Nameplate Value)	0 A

Certifications and Approvals

UL	508
CSA	C22.2 No. 14
IEC	947-3 Low Voltage Switchgear and Controlgear part 3
CE	
CSA	CSA22.2 No. 4
IEC	947-3/ EN60947-3 Low Voltage Switchgear and Controlgear part 3
BS	EN60947-3
VDE0660	
NEMA	KS-1 UL 1087/489
ASTA	Certified
LOVAG	Certified
UL	98