


# Product Details

## Product: 20AB9P6A0AYNANNN

Description: PowerFlex70 AC Drive, 240 (208) VAC, 3 PH, 9.6 Amps, 3 HP Normal Duty, 2 HP Heavy Duty, Panel Mount - IP20 / NEMA Type 1, No HIM (Blank Plate), Brake IGBT Installed, Without Drive Mounted Brake Resistor, Second Environment Filter per CE EMC directive (89/336/EEC), No Communication Module, Standard Control, No Feedback

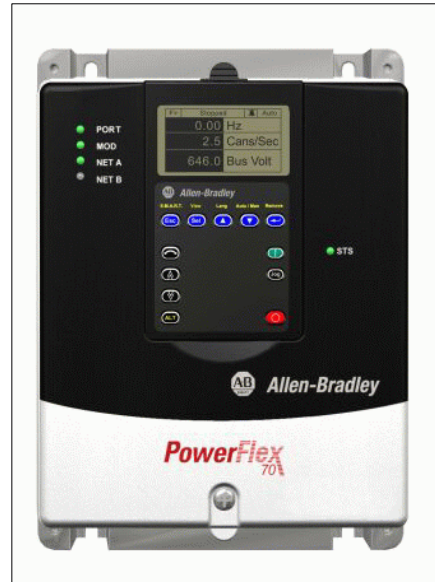

### ***BASE DRIVE INFORMATION***

---

Input Voltage	240 (208) VAC, 3 PH
Current Rating	9.6 Amps
Enclosure	Panel Mount - IP20 / NEMA Type 1
Frame Size	Frame Size B
Output Current Information	Output Amps: 9.6A Cont, 10.6A 1 Min, 14.4A 3 Sec
Stock Product Program	No

### ***INSTALLED OPTIONS***

---

Control and I/O	Standard Control
Human Interface Module	No HIM (Blank Plate)
Documentation	User Manual
Brake IGBT	Brake IGBT Installed
Brake Resistor	Without Drive Mounted Brake Resistor
Filter Options	Second Environment Filter per CE EMC directive (89/336/EEC)
Internal Communication Module	No Communication Module
Feedback option	No Feedback

### ***Dimensions and Weight***

---

Weight (kg / lbs)	3.58 / 7.88
-------------------	-------------