


Product Details

Product: 20AB9P6A0AYNNNNN

Description: PowerFlex70 AC Drive, 240 (208) VAC, 3 PH, 9.6 Amps, 3 HP Normal Duty, 2 HP Heavy Duty, Panel Mount - IP20 / NEMA Type 1, No HIM (Blank Plate), Brake IGBT Installed, Without Drive Mounted Brake Resistor, without CE compliant filter, No Communication Module, Standard Control, No Feedback

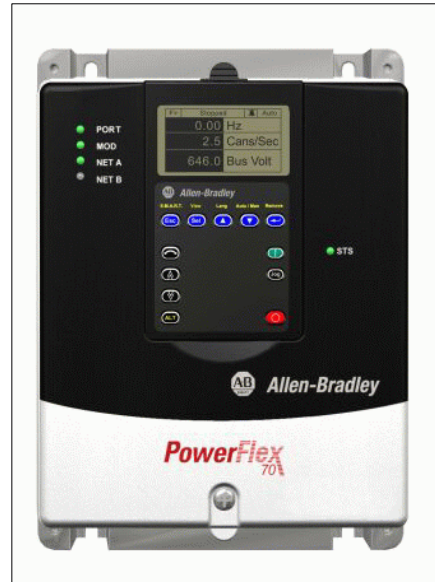

BASE DRIVE INFORMATION

| | |
|----------------------------|--|
| Input Voltage | 240 (208) VAC, 3 PH |
| Current Rating | 9.6 Amps |
| Enclosure | Panel Mount - IP20 / NEMA Type 1 |
| Frame Size | Frame Size B |
| Output Current Information | Output Amps: 9.6A Cont, 10.6A 1 Min, 14.4A 3 Sec |
| Stock Product Program | No |

INSTALLED OPTIONS

| | |
|-------------------------------|--------------------------------------|
| Control and I/O | Standard Control |
| Human Interface Module | No HIM (Blank Plate) |
| Documentation | User Manual |
| Brake IGBT | Brake IGBT Installed |
| Brake Resistor | Without Drive Mounted Brake Resistor |
| Filter Options | without CE compliant filter |
| Internal Communication Module | No Communication Module |
| Feedback option | No Feedback |

Dimensions and Weight

| | |
|-------------------|-------------|
| Weight (kg / lbs) | 3.58 / 7.88 |
|-------------------|-------------|