


# Product Details

## Product: 20AC022A0AYNANN

Description: PowerFlex70 AC Drive, 400 VAC, 3 PH, 22 Amps, 11 kW Normal Duty, 7.5 kW Heavy Duty, Panel Mount - IP20 / NEMA Type 1, No HIM (Blank Plate), Brake IGBT Installed, Without Drive Mounted Brake Resistor, Second Environment Filter per CE EMC directive (89/336/EEC), No Communication Module, Standard Control, No Feedback

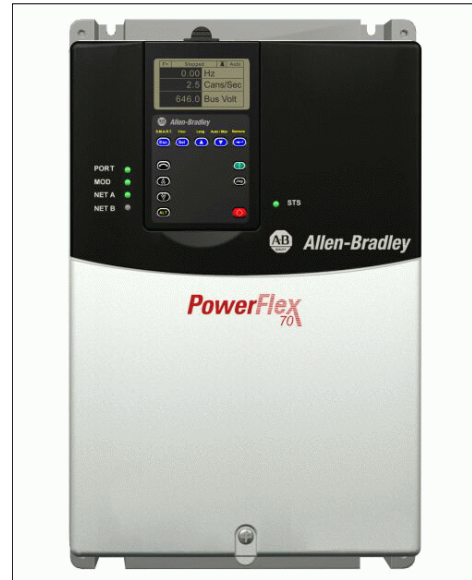

### ***BASE DRIVE INFORMATION***

---

Input Voltage	400 VAC, 3 PH
Current Rating	22 Amps
Enclosure	Panel Mount - IP20 / NEMA Type 1
Frame Size	Frame Size D
Output Current Information	Output Amps: 22A Cont, 24.2A 1 Min, 33A 3 Sec
Stock Product Program	No

### ***INSTALLED OPTIONS***

---

Control and I/O	Standard Control
Human Interface Module	No HIM (Blank Plate)
Documentation	User Manual
Brake IGBT	Brake IGBT Installed
Brake Resistor	Without Drive Mounted Brake Resistor
Filter Options	Second Environment Filter per CE EMC directive (89/336/EEC)
Internal Communication Module	No Communication Module
Feedback option	No Feedback

### ***Dimensions and Weight***

---

Weight (kg / lbs)	8.98 / 19.8
-------------------	-------------