


Product Details

Product: 20AD014A0AYNANN

Description: PowerFlex70 AC Drive, 480 VAC, 3 PH, 14 Amps, 10 HP Normal Duty, 7.5 HP Heavy Duty, Panel Mount - IP20 / NEMA Type 1, No HIM (Blank Plate), Brake IGBT Installed, Without Drive Mounted Brake Resistor, Second Environment Filter per CE EMC directive (89/336/EEC), No Communication Module, Standard Control, No Feedback

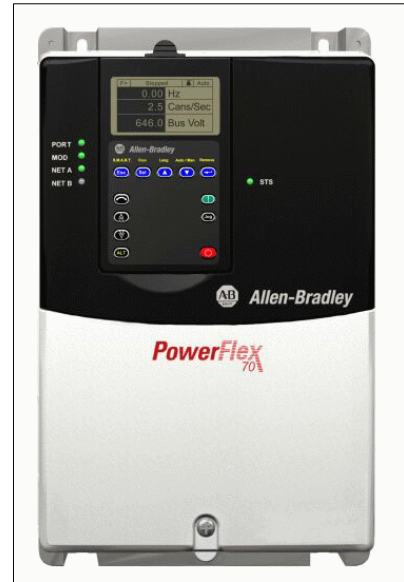

BASE DRIVE INFORMATION

Input Voltage	480 VAC, 3 PH
Current Rating	14 Amps
Enclosure	Panel Mount - IP20 / NEMA Type 1
Frame Size	Frame Size C
Output Current Information	Output Amps: 14A Cont, 16.5A 1 Min, 22A 3 Sec
Stock Product Program	No

INSTALLED OPTIONS

Control and I/O	Standard Control
Human Interface Module	No HIM (Blank Plate)
Documentation	User Manual
Brake IGBT	Brake IGBT Installed
Brake Resistor	Without Drive Mounted Brake Resistor
Filter Options	Second Environment Filter per CE EMC directive (89/336/EEC)
Internal Communication Module	No Communication Module
Feedback option	No Feedback

Dimensions and Weight

Weight (kg / lbs)	6.89 / 15.2
-------------------	-------------