


# Product Details

## Product: 20AD3P4A0AYNNNNN

Description: PowerFlex70 AC Drive, 480 VAC, 3 PH, 3.4 Amps, 2 HP Normal Duty, 1.5 HP Heavy Duty, Panel Mount - IP20 / NEMA Type 1, No HIM (Blank Plate), Brake IGBT Installed, Without Drive Mounted Brake Resistor, without CE compliant filter, No Communication Module, Standard Control, No Feedback

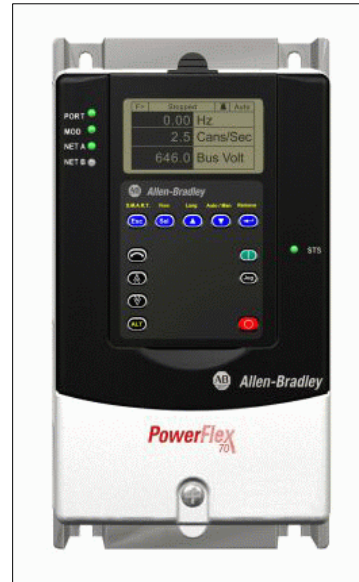

### ***BASE DRIVE INFORMATION***

---

Input Voltage	480 VAC, 3 PH
Current Rating	3.4 Amps
Enclosure	Panel Mount - IP20 / NEMA Type 1
Frame Size	Frame Size A
Output Current Information	Output Amps: 3.4A Cont, 4.5A 1 Min, 6A 3 Sec
Stock Product Program	No

### ***INSTALLED OPTIONS***

---

Control and I/O	Standard Control
Human Interface Module	No HIM (Blank Plate)
Documentation	User Manual
Brake IGBT	Brake IGBT Installed
Brake Resistor	Without Drive Mounted Brake Resistor
Filter Options	without CE compliant filter
Internal Communication Module	No Communication Module
Feedback option	No Feedback

### ***Dimensions and Weight***

---

Weight (kg / lbs)	2.72 / 5.98
-------------------	-------------