


Product Details

Product: 20AE017A0AYNNNNN

Description: PowerFlex70 AC Drive, 600 VAC, 3 PH, 17 Amps, 15 HP Normal Duty, 10 HP Heavy Duty, Panel Mount - IP20 / NEMA Type 1, No HIM (Blank Plate), Brake IGBT Installed, Without Drive Mounted Brake Resistor, without CE compliant filter, No Communication Module, Standard Control, No Feedback

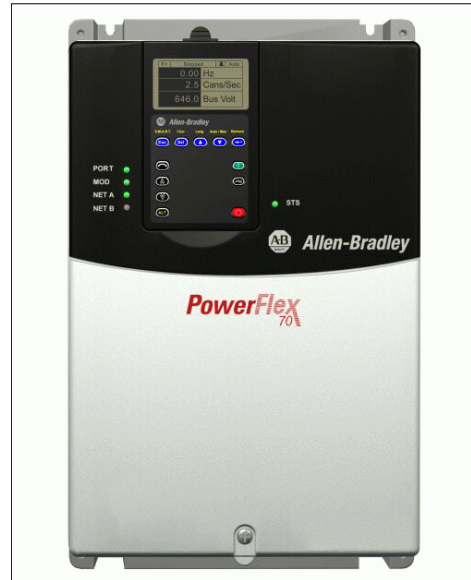

BASE DRIVE INFORMATION

Input Voltage	600 VAC, 3 PH
Current Rating	17 Amps
Enclosure	Panel Mount - IP20 / NEMA Type 1
Frame Size	Frame Size D
Output Current Information	Output Amps: 17A Cont, 18.7A 1 Min, 25.5A 3 Sec
Stock Product Program	No

INSTALLED OPTIONS

Control and I/O	Standard Control
Human Interface Module	No HIM (Blank Plate)
Documentation	User Manual
Brake IGBT	Brake IGBT Installed
Brake Resistor	Without Drive Mounted Brake Resistor
Filter Options	without CE compliant filter
Internal Communication Module	No Communication Module
Feedback option	No Feedback

Dimensions and Weight

Weight (kg / lbs)	8.98 / 19.8
-------------------	-------------