

Rail & Base Mount Terminal Blocks



MAGNUM[®]
GET CONNECTED WITH US

NC3

Inches (Millimeters)

SPECIFICATIONS

 - Rating:** 175A, 600V; UL/CSA
- Center spacing:** 1.06" (26.92)
- Number of poles:** 3
- Circuits per foot:** 11
- Wire size:** 2/0-#14 CU/AL
- Screw size:** 5/16-24
- Mounting options:** C-rail, Base Mount
- Marking tape:** MT12-1/2
- Torque rating:** 45 in/lb max.
- Operating temperature:** 105°C

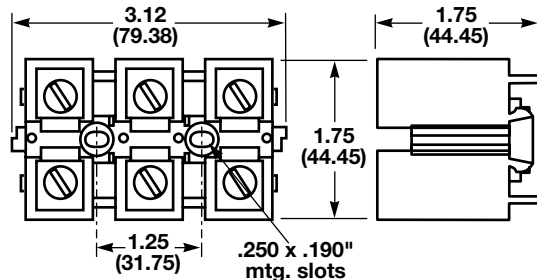

Optional LS3 Terminal Cover