

## Color-Keyed®

**T&B Catalog Number:****60244****UPC Number:**

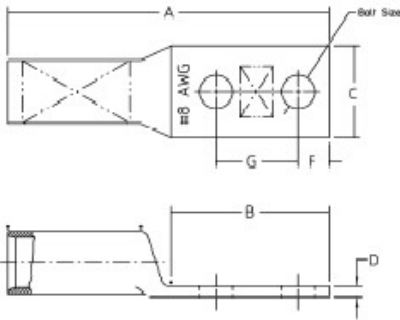
78621060244

**Description:**

Aluminum Two-Hole Lug - Straight Long Barrel - max 35KV, 3/0 AWG Wire, 1/2" Bolt Size, 1 3/4" Hole Spacing, Tin Plated Blind End, Ruby 60

**Status:**

Active

**General**

Material	Aluminum
Finish	Tin Plated
Wire Size	3/0 AWG
Number of Studs	2
Stud Size	1/2
Bolt Hole Spacing	1 3/4
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Ruby
Die Code	60

**Dimension Information**

A (inches)	5.16
B (inches)	3.41
C (inches)	1.063
D (inches)	0.22
E (inches)	0.77
F (inches)	0.75
G (inches)	1.75

**Packaging**

T&B Order Multiple	5
T&B Inner Pack	5
Package in Units	50
T&B Sold in UOM	Each
T&B Weight Per UOM	17.1 lbs. per 100

**Application Support**

T&B Instruction Sheets	ta00880-tb2
Overview	Available on Website
Connector & Tooling Chart	Available on Website

**Notes**

Dimensions given for reference only. Dimensions may vary up to +/- .030.

**Certifications**

RoHS Compliance	Yes
-----------------	-----

### Certifications



File Nbr:  
E9809

**For further technical assistance, please contact us...**

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)