


Cross Reference with 40120-426-01

## Product Details and Certifications

**Product:** 1492-EC85

**Description:** Panel Mount Block, Pull apart, 5-Pole, Brown, Pkg. Qty. of 1

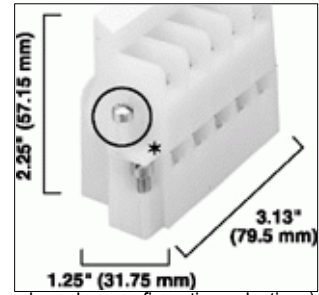

Representative Photo Only (actual product may vary based on configuration selections)

### ***PANEL MOUNT BLOCK DATA***

Base Block Type	Pull-Apart Blocks
Number of Poles	5 pole
Terminal Type	Standard

### ***Certifications and Approvals***

UR

CSA

For UL Certifications Directory:

<http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm>

## SPECIFICATION SHEET FOR 1492-EC85

<b>Specifications</b>	<i>5-pole terminal block. Pulls apart to disconnect all poles from the circuit.</i>	
Approvals (See Page 12-7)	<b>UL/CSA</b>	
Voltage Rating	600V AC/DC	
Maximum Current (per pole)	25 A	
Wire Range (Rated Cross Section)	#20...#12 AWG (0.75...4 mm <sup>2</sup> )	
Wire Strip Length	0.38" (9.7 mm)	
Recommended Tightening Torque	6...16 lb-in. (0.7...1.8 Nm)	
Insulation Temperature Range	-40...+221°F (-40...+105°C)	
<b>Terminal Blocks</b>	<b>Cat. No.</b>	<b>Pcs./ Pkg.</b>
Terminal Block:	1492-EC85	1
<b>Accessories</b> (page 12-172)	<b>Cat. No.</b>	<b>Pcs./ Pkg.</b>
Anchor Unit: (required every 12th block)	Not Required	—
End Piece	Not Required	—