


Product Details

Product: 500FL-BOD93

Description: NEMA AC Contactor, Non-Motor Loads, Feed-Through, 30A

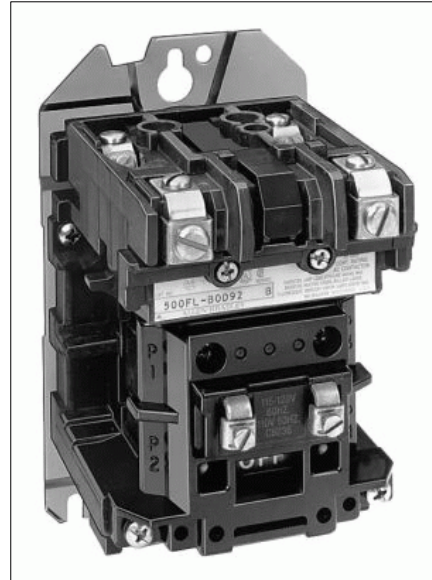

MOTOR DATA

Maximum Ampere Rating	30A All Non-Motor and Lighting Loads
-----------------------	--------------------------------------

CONTACTOR DATA

Enclosure Type	Open
Coil Voltage	115-120V 60Hz
Pole Configuration	3 Power Poles

Certifications and Approvals

NEMA/EEMAC	ICS2 (Industrial Controls and Systems)
UL	508
CSA	22.2, No. 14
ABS	4/5.115
USCG	46 CFR 111.70
IEEE	45
UL	Listed (File No. E3125; Guide No. NLDX)
CSA	Certified (LR1234)
NPKR	File No. E10314; Guide No. NPKR
CE	Marked (Per EN 60947)
ABS	American Bureau of shipping

Recommended Spare Parts

CB-236	1	COIL, 120V/60HZ 110V/50HZ FOR STARTER OR CONTACTOR
40410-331-52	3	KIT, SIZE 1 CONTACT FOR CONTACTOR OR STARTER