


Product Details and Certifications

Product: 505-FOD-A2N-87A

Description: NEMA Full Voltage Reversing Starter, SIZE 5, with E1 Plus Solid-State Overload Relay

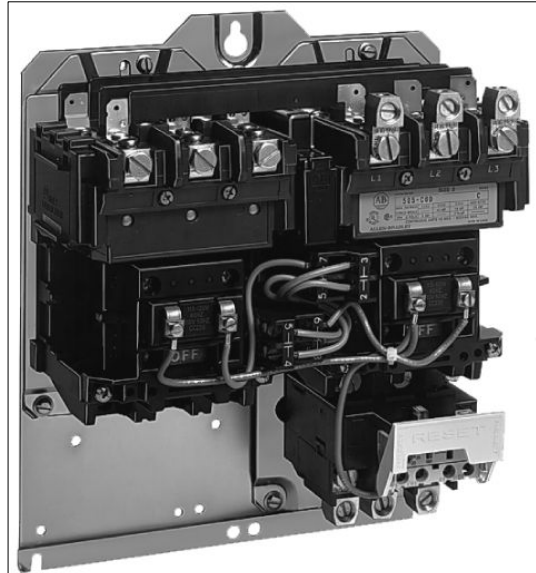

Representative Photo Only (actual product may vary based on configuration selections)

SYSTEM VOLTAGE DATA

Phases 3 Phase

STARTER DATA

NEMA Size NEMA 5
 Enclosure Type Open
 Vertically Arranged Starter No
 Coil Voltage 115-120V 60Hz

OPTIONS

Overload Relay
 -A2N E1 Plus Solid State
 Factory Installed Modifications Timer, On Delay, Contactor mounted

IMPORTANT INFORMATION

Enclosure Size [length x width x depth] Open Style / Unknown

Certifications and Approvals

NEMA/EEMAC ICS 2 (Industrial Controls and Systems)
 UL 508
 CSA 22.2, No. 14
 ABS 4/5.115
 USCG 46 CFR 111.70
 IEEE 45
 UL Listed (File No. E3125; Guide No. NLDX, NLDX2, NPKR)
 CSA Certified (LR 1234)
 CE Marked (Per EN 60947)
 ABS American Bureau of shipping
 For UL Certifications Directory: <http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm>

Recommended Spare Parts

CB-236	2	COIL,120V/60HZ 110V/50HZ FOR STARTER OR CONTACTOR
AF-236	2	COIL,120V/60HZ 110V/50HZ FOR STARTER OR CONTACTOR

Short Circuit Ratings Data Sheet for 505-FOD-A2N-87A

Operational Rating	Dual Element Time Delay Fuses			Non-Time Delay Fuses			Circuit Breakers							Rating Reference	File Ref: UL
	SCCR [kA]	Max Fuse Size [A]	Fuse Class	SCCR [kA]	Max Fuse Size [A]	Fuse Class	CB Type	Catalog Number	SCCR [kA]	SCCR [kA]	SCCR [kA]	SCCR [kA]	SCCR [kA]		
	600V			600V					240V	480V	480Y/277V	600V	600Y/347V		
—	100	400	R	—	—	—			—	—	—	—	—	Label with Product	E312
—	100	600	J	—	—	—			—	—	—	—	—	Label with Product	E312