


Product: 505V-FOI-XXX
Description: 505 NEMA Full Voltage Reversing Starter

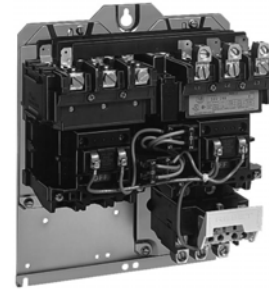

Representat
Photo Only (actual product may vary base
on configuration selections)

SYSTEM VOLTAGE DATA

Supply Voltage 415V 50Hz
 Phases 3 Phase

STARTER DATA

Horsepower 150 HP
 NEMA Size NEMA 5
 Enclosure Type Open
 Vertically Arranged Starter Yes
 Coil Voltage 415V 50Hz

OPTIONS

Overload Relay Provision for Mounting an Overload Relay (field installation)

IMPORTANT INFORMATION

Enclosure Size [length x width x depth] Open Style / Unknown

CERTIFICATIONS AND APPROVALS

NEMA/EEMAC ICS 2 (Industrial Controls and Systems)
 UL 508
 CSA 22.2, No. 14
 ABS 4/5.115
 USCG 46 CFR 111.70
 IEEE 45
 UL Listed (File No. E3125; Guide No. NLDX, NLDX2, NPKR)
 CSA Certified (LR 1234)
 CE Marked (Per EN 60947)
 ABS American Bureau of shipping
 For UL Certifications Directory: <http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm>