


# Product Details

## Product: 509-FOA

Description: NEMA Full Voltage Non-Reversing Starter, SIZE 5, 230-240V 60Hz, Open, with Eutectic Alloy Overload Relay

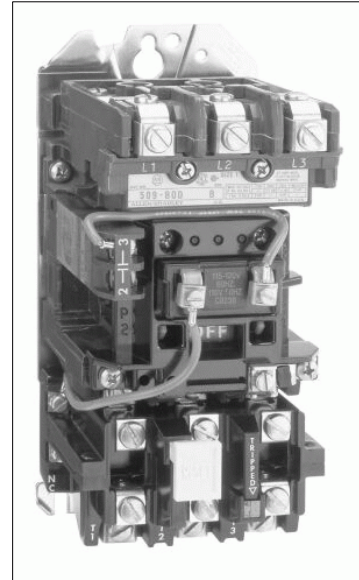

### ***SYSTEM VOLTAGE DATA***

---

Supply Voltage	240V 60Hz
Phases	3 Phase

### ***STARTER DATA***

---

Horsepower	100 HP
NEMA Size	NEMA 5
Enclosure Code	Open
Control Voltage	230-240V 60Hz

### ***OPTIONS***

---

Overload Relay	Eutectic Alloy
Solenoid Option	No

### ***Certifications and Approvals***

---

NEMA/EEMAC	ICS 2 (Industrial Controls and Systems)
UL	508
CSA	22.2, No. 14
ABS	4/5.115
USCG	46 CFR 111.70
UL	Listed (File No. E3125; Guide No. NLDX)
CSA	Certified (LR 1234)
CE	Marked (Per EN 60947)
ABS	American Bureau of shipping

### ***Recommended Spare Parts***

---

AF-254	1	COIL, 240V/60HZ 220V/50HZ FOR STARTER OR CONTACTOR
--------	---	--