

Product Details and Certifications

Cross Reference RA Part Number: 800F-11WS113



Product: 800F-11WS113

Description: 800F Legend Plate, 30 X 40mm Std., 2 Piece Snap-In (Plate and Frame), Spanish, White with Black Legend Text, 22.5mm Opening



Representative Photo Only (actual product may vary based on configuration sections)

ACCESSORY SELECTION

Accessories	Legend Plates
Packaging	Standard Pack, Quantity: 1
Legend Text	(Spanish)

CERTIFICATIONS AND APPROVALS

UR
CSA
CE
CCC

For UL Certifications Directory:

<http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm>

22.5 mm Push Buttons

Accessories

Legend Plates

Ordering Information*§

Standard Text/Symbols

1. Select the cat. no. for the appropriate legend size and color from the Selection Tables on this page.
2. Complete the cat. no. by adding the appropriate suffix no. selected from pages 10-116...10-119. Font size is automatically determined by the number of characters, as shown in the following table. Do not add the font code to the cat. no.

Font Size	No. of Characters		
	One-Piece Legend Plate	Two-Piece Legend Plate	Special Multi-Function Legend Plate
K (small)	>14	>13	>6
S (standard)	≤14	≤13	≤6

Example: **Cat. No. 800F-11WE101** identifies a white, 30 x 40 mm snap-in legend plate and frame with AUTO engraved on it.



Custom Text (text found on pages 10-116...10-119)

1. Select the cat. no. for the appropriate legend size and color from the Selection Tables on this page.
2. Add **E100** followed by the font code (K, S, L) from the following table.


Font Size	Type of Legend Plate							
	One-Piece						Special Multi-Function	
	Max. Char. per Line	Max. No. of Lines		Max. Char. per Line	Max. No. of Lines		Max. Char. per Line	Max. No. of Lines
		30 x 40 mm	30 x 50 mm		30 x 40 mm	30 x 50 mm or 30 x 60 mm		
K (small)	16	2	5	15	2	5	7	3
S (standard)	14	2	3	13	1	3	6	3
L (large)	10	1	3	9	1	3	4	2

3. Complete the cat. no. by adding custom text to the order item's memo text or notes field.

Example: **Cat. No. 800F-12WE100K**, with **STARTER** text entered into memo text on order, identifies a white, 30 x 50 mm snap-in legend plate and frame with custom text STARTER engraved in small font.



Selection Tables*

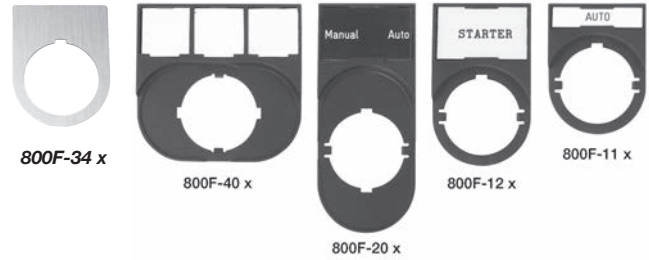

Type	Description	Cat. No. (Blank)	Cat. No. (with Text Symbols)
30 x 40 mm 2-piece snap-in plate and frame	Red with white text	800F-11RE100	800F-11R
	White with black text	800F-11WE100	800F-11W
	Black with white text	800F-11BE100	800F-11B
30 x 50 mm 2-piece snap-in plate and frame	White with black text	800F-12WE100	800F-12W
	Black with white text	800F-12BE100	800F-12B
	Aluminum with black text	800F-12AE100	800F-12A
30 x 60 mm 2-piece snap-in plate and frame	White with black text	800F-20WE100	800F-20W
	Black with white text	800F-20BE100	800F-20B
	Aluminum with black text	800F-20AE100	800F-20A
Special multi-function 4-piece snap-in plates and frame	White with black text	800F-40WE100	—
	Black with white text	800F-40BE100	—
	Aluminum with black text	800F-40AE100	—
30 x 40 mm 1-piece	Red with white text	800F-34RE100	800F-34R
	White with black text	800F-34WE100	800F-34W
	Black with white text	800F-34BE100	800F-34B
	Aluminum with black text	800F-34AE100	800F-34A
30 x 50 mm 1-piece	Red with white text	800F-35RE100	800F-35R
	White with black text	800F-35WE100	800F-35W
	Black with white text	800F-35BE100	800F-35B
	Aluminum with black text	800F-35AE100	800F-35A
30 x 40 mm snap-in plate only	Red with white text	800F-17RE100	800F-17R
	White with black text	800F-17WE100	800F-17W
	Black with white text	800F-17BE100	800F-17B
30 x 50 mm snap-in plate only	White with black text	800F-18WE100	800F-18W
	Black with white text	800F-18BE100	800F-18B
	Aluminum with black text	800F-18AE100	800F-18A
Special multi-function snap-in plate only‡	White with black text	800F-42WE100	800F-42W
	Black with white text	800F-42BE100	800F-42B
	Aluminum with black text	800F-42AE100	800F-42A
30 x 66 mm 1-piece	Yellow with black text	800F-37YE100	800F-37Y

Text symbols available in next page

Legend Plate Frame — 2-Piece Snap-In*

Type	Cat. No.	Type	Cat. No.
30 x 40 mm	800F-110	30 x 60 mm	800F-200
30 x 50 mm	800F-120	Special multi-function‡	800F-400

* Blank legend frames sold only in multiples of 10. Order (quantity of) 10 to receive one package of 10 pieces. Legends with standard text/symbols or custom text are packaged in quantities of 1.

§ Font code **K** = 0.08 in; font code **S** = 0.10 in; font code **L** = 0.14 in.

‡ Three snap-in plates are required for each legend frame.

§ For configuration assistance, see RAISE product selection software.

* Plate dimensions found on pages 10-122...10-123.



Legend Texts, Continued
Standard Text, Continued*

French

Marking	Suffix No.	Marking	Suffix No.	Marking	Suffix No.	Marking	Suffix No.	Marking	Suffix No.
A-COUPS	F138	AVANT-ARRÊT-ARRIÈRE	F122	DESCENDRE	F110	HORS MANUEL	F249	MARCHE-ARRÊT	F211
ACCU-STOP	F280			DROIT	F191	LENT	F201	MONTER	F182
ARRIÈRE	F188	AVANT-ARRIÈRE	F124	EN	F247	LENT-ARRÊT-VITE	F205	OUVRIR	F170
ARRÊT	F163	AV-ARR	F290	EN CIRCUIT	F245	M FORCEE	F284	PANNE	F113
ARRÊT D'ENTR	F289	AV-HORS-ARR	F253	EN MANUEL	F250	MANUEL	F126	RAP-HORS-LENT	F285
ARRÊT DOUX	F288	BAS	F148	FERMER	F107	MANUEL-ARRÊT-AUTO	F128	RAPIDE	F114
ARRÊT D'URGENCE	F112	BAS-ARRÊT-HAUT	F150	FREINAGE	F105			RÉGLER	F198
ARRÊT-MANUEL	F251	DEMAR. D-ENTR	F283	GAUCHE	F145	MANUEL-AUTO	F127	SURCHARGE	F254
ARRÊT-MARCHE	F165	DEMAR.-MAN.	F252	HAUT	F129	MANUEL-HORS-AUTO	F157	VARIATEUR ALIMENTÉS	F293
ARRÊT POMPE	F286	DÉRIV-ARRÊT-EFN	F294	HAUT-HORS-BAS	F131			VIT. ATTEINT	F281
AUTO	F101	DÉRIV ARRÊT	F295	HORS	F246	MARCHE	F166	VIT. LENTE	F287
AUTO-MANUEL	F282	DÉRIV MARCHE	F296	HORS CIRCUIT	F244	—	—	VITESSE	F291
AVANT	F120	DÉRIVATION ALIMENTÉS	F292	HORS-EN	F248	—	—	—	—

Spanish

Marking	Suffix No.	Marking	Suffix No.	Marking	Suffix No.	Marking	Suffix No.	Marking	Suffix No.
ABRIR	S170	ARRANQUE	S166	DERECHA	S191	MARCHA	S208	PARADA-MARCHA	S165
ADELANTE	S120	ATRÁS	S188	EN SERVICIO	S243	MARCHA-PARO	S211	PARO	S163
ADELANTE-ATRÁS	S124	BAJADA	S152	IZQUIERDA	S145	PARADA	S212	SUBIDA	S182
ADELANTE-PARADA-ATRÁS	S123	BAJAR	S110	MANUAL	S126	PARADA DE EMERGENCIA	S112	SUBIR	S223
		CERRAR	S107	MANUAL-AUTO	S127			—	—

German

Marking	Suffix No.	Marking	Suffix No.	Marking	Suffix No.	Marking	Suffix No.	Marking	Suffix No.
AB	G110	EINRICHTEN	G198	LANGSAM	G201	ÖFFNEN	G170	VOR	G120
AUF	G223	HAND	G126	LINKS	G145	RECHTS	G191	VOR-AUS-ZURÜCK	G122
AUS	G163	HAND-AUS-AUTO	G128	LINKS-RECHTS	G146	SCHNELL	G114	VOR-ZURÜCK	G124
AUS-EIN	G165	HAND-AUTO	G127	NIEDRIG	G148	SENKEN	G152	ZU	G107
BETRIEB	G243	HEBEN	G182	NIEDRIG-AUS-HOCH	G150	STÖRUNG	G113	ZURÜCK	G188
EIN	G166	HOCH	G129	NOT AUS	G112	—	—	—	—

Italian

Marking	Suffix No.	Marking	Suffix No.	Marking	Suffix No.	Marking	Suffix No.	Marking	Suffix No.
ABBASSARE	T152	AVANTI-DISINS-INDIETRO	T122	DISCESA	T110	IN SERVIZIO	T243	MARCIA-ARRESTO	T211
ALTO	T129			DISINS-INS	T165	LENTO	T201	PREPARARE	T198
APRIRE	T223	AVANTI-INDIETRO	T124	DISINSERITO	T163	MANUALE	T126	RAPIDO	T114
ARRESTO	T212	BASSO	T148	DISTURBO	T113	MANUALE-AUTO	T127	ROTAZIONE CW	T246
ARRESTO EMERGENZA	T112	BASSO-DISINS-ALTO	T150	EMERGENZA	T248	MANUALE-DISINS-AUTO	T128	ROTAZIONE CCW	T247
		DESTRA	T191	INDIETRO	T188			SALITA	T182
AUTOMATICO	T101	CHIUDERE	T107	INSERITO	T166	MARCIA	T208	SINISTRA	T145
AVANTI	T120	—	—	—	—	—	—	—	—

Swedish

Marking	Suffix No.	Marking	Suffix No.	Marking	Suffix No.	Marking	Suffix No.	Marking	Suffix No.
BACK	N188	HÖGER	N191	NERN	110	UPP	N223	VÄNSTER	N145
FRAM	N120	—	—	—	—	—	—	—	—

* Items in grey shaded table cells only available on legend plates. Not available as laser-engraved text on button caps, illuminated push button diffusers, or pilot light diffusers.

§ Not available on -34 legend plates.

* Not available on -35 legend plates.

> Not available on -42 legend plates.

* Only available on legend plates and AD2 or AD4 diffusers.