


Product Details and Certifications

Cross Reference RA Part Number: 800T-PST16C N

 **Product: 800T-PST16C**

Description: 800T Small Pilot Light, Clear, Transformer, Push-to-Test, 120V AC 50/60 Hz

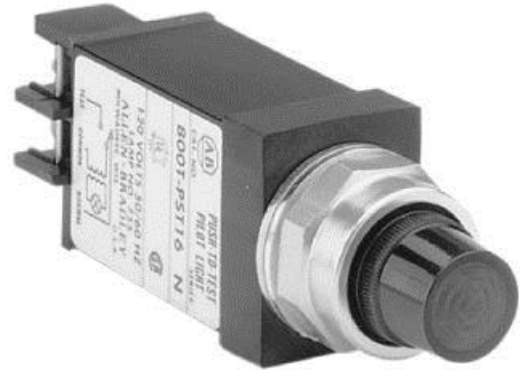

Representative Photo Only (actual product may vary based on configuration selections)

PILOT LIGHT DATA

Power Module Type	Transformer (or Dual Input)
Lamp Test Options	Push-to-Test
Power System	Transformer Type
Illumination Options	Incandescent Lamp
Voltage	120V AC 50/60 Hz
Lens Color	Clear

CERTIFICATIONS AND APPROVALS

UL	Listed E14840, E10314; Guide #NKCR, NOIV
CSA	LR1234, LR11924, 22.2 #14
CE	60947-5-1
For UL Certifications Directory:	http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm


RECOMMENDED SPARE PARTS

800T-N243	LOCKING RING ①
800T-N293	THRUST WASHER
800T-N292	TRIM WASHER
40271-095-01	GASKET


① Locking Ring repair parts are for Series N and later devices. For illuminated selector switches, see footnote 2.

② Locking Ring repair parts are for Series U units only. For Series T units, replace the entire device

18 mm Small Pilot Lights Type 4/13, Class I, Division 2

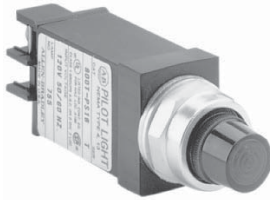


18 mm Pilot Light
 Cat. No. 800T-PS16R

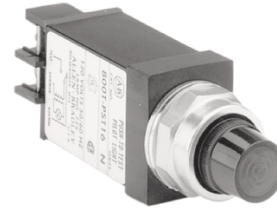

18 mm Push-to-Test Pilot Light
 Cat. No. 800T-PST16R

Type	Lamp	Voltage	Color	Pilot Light	Push-To-Test
				Cat. No.	Cat. No.
Transformer	Incandescent	120V AC 50/60 Hz	Red	800T-PS16R	800T-PST16R
	LED			800T-PSH16R	800T-PSTH16R
Dual Input Diode	Incandescent	120V AC		800T-PSD16R	—
		24V AC/DC		800T-PSD24R	—
Dual Input Transformer	Incandescent	120V AC/DC 50/60 Hz		800T-PSDT16R	—
Full Voltage	Incandescent	24V AC/DC		800T-QS24R	800T-QST24R
		24V AC/DC		800T-QSH24R	800T-QSTH24R
	LED	120V AC		800T-QSH10R	800T-QSTH10R
		Neon		120V AC/DC	800T-RS10A

800T - PS T c 16 C
 a b c d e

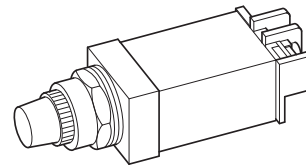

a

Power Module Type	
Code	Description
PS	Transformer (or dual input)
QS	Full voltage
RS	Neon*

c

Illumination Options	
Transformer/Full Voltage/Dual Input	
Code	Description
Blank	Incandescent
H	LED‡
Neon	
Blank	No options

e

Lens Color	
Plastic	
Code	Description
Blank	No lens
A	Amber
B	Blue
C	Clear
G	Green
R	Red
W	White

b

Lamp Test Options	
Code	Description
Blank	No test option
D	Dual input diode
DT	Dual input transformer relay >
T	Push-to-test >

d

Voltage	
Transformer	
Code	Description
16	120V AC 50/60 Hz
26	240V AC 50/60 Hz
Full Voltage Incandescent	
12	12V AC/DC
24	24V AC/DC
Full Voltage LED	
10	120V AC
13	130V AC/DC
24	24V AC/DC
Neon	
10	120V AC/DC
20	240V AC/DC
Dual Input	
16	120V AC 50/60 Hz
24	24V AC/DC*

* Neon is only available in amber or clear.
 ‡ LEDs available in red, green, amber, blue, and white. LED color matches lens color, except clear lens supplied with white LED and white lens supplied with amber LED. All LEDs except 120V have an internal shunt resistor for use with solid-state outputs.
 † Dual input diode only.
 > Class 1, Division 2 rating not available. Push-to-test rated for Type 13 only.