



Cross Reference RA Part Number PN-101832

THREE PHASE DRY TYPE TRANSFORMER
ALLEN-BRADLEY
 MILWAUKEE, WI. USA

SP® LR3902 AU® E112313 P/N PN-101832

VOLTS	% RATED VOLTAGE	CONNECTION
504	105	1-2
492	102.5	2-3
480	100	3-4
468	97.5	4-5
456	95	5-6

198118 40022-053-02 TP1
 COPPER WINDING
 MEETS TP-1-2002 EFFICIENCY

HV 480V LV 208Y/120V

BILL kV - TEMP. CLASS 180

H1 H2 H3 X0 X1 X2 X3

IMPEDANCE % @ 100 °C 4.4

ENCL. TYPE - WEIGHT LBS 355

INS. SYSTEM 180-1 SERIAL NO: cab3001e




Hammond Power Solutions Inc.

TITLE: 3PH DISTRIBUTION TRANSFORMER
NAMEPLATE INFORMATION


NO.	DATE	BY	REVISION	DES: MCHRISTM
				DATE: 11/01/18
				SCALE: NTS

SHEET 1 OF 2


EDB 198118

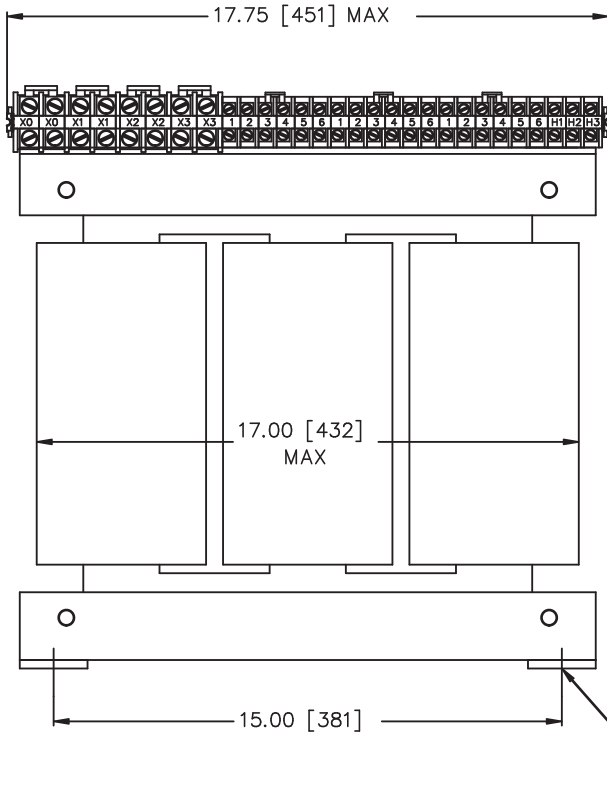

FRONT_VIEW

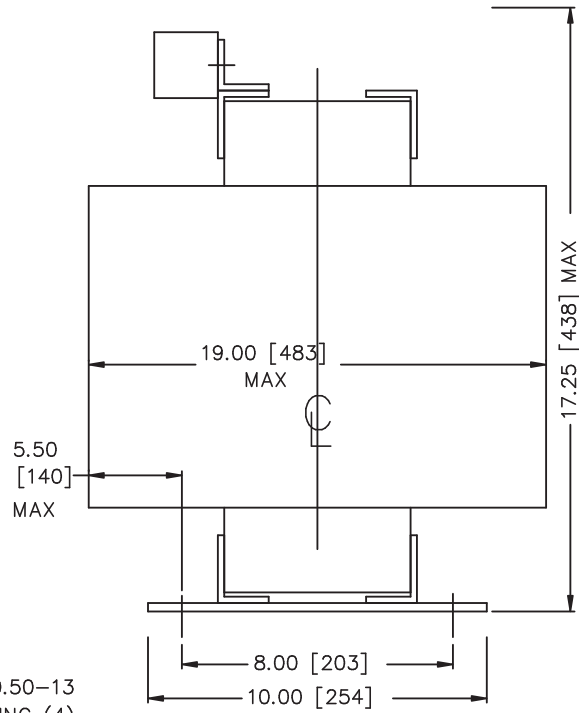

SIDE_VIEW

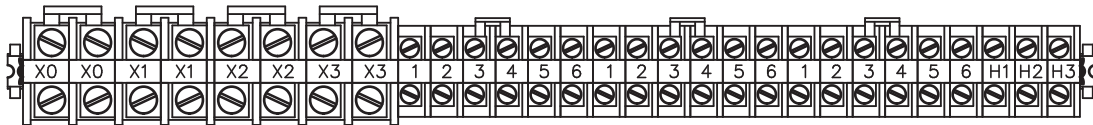

TERMINAL_BLOCK_DETAIL



TITLE: 3PH DISTRIBUTION TRANSFORMER
MECHANICAL INFORMATION

				DES: MCHRISTM
				DATE: 11/01/18
NO.	DATE	BY	REVISION	SCALE: NTS

SHEET 2 OF 2

EDB 198118