



# RB SERIES

## RELAY SOCKETS



<b>DESCRIPTION</b>	8 and 11 Pin Octal Sockets	
<b>ELECTRICAL RATING</b>	<ul style="list-style-type: none"> <li>• RB08, RB08-PC - 600 Volts, 10 Amps</li> <li>• RB11, RB11-PC - 300 Volts, 10 Amps</li> </ul>	
<b>CONSTRUCTION</b>	<b>Contacts</b> • Brass, Nickel Plated <b>Screws</b> • 6 - 32 x 5/16" Steel, Zinc Plated; Pressure Clamp Wire Range #12-#22 Solid or Stranded <b>Molding</b> • Break Resistant Thermoplastic	
<b>AGENCY APPROVALS</b>	<ul style="list-style-type: none"> <li>• UL recognized, File No. E60008</li> <li>• CSA certified, File No. LR29513</li> </ul>	 


### ORDERING CODE

PART NO.	DESCRIPTION	TERMINAL TYPE
RB08	DPDT, 8 Pin Octal (Fig. 1)	Binder Head Screws
RB08-PC	DPDT, 8 Pin Octal (Fig. 1)	Pressure Clamp Screws
RB11	3PDT, 11 Pin Octal Style (Fig. 2)	Binder Head Screws
RB11-PC	3PDT, 11 Pin Octal Style (Fig. 2)	Pressure Clamp Screws



CUSTOM CONNECTOR

**Fig. 1**

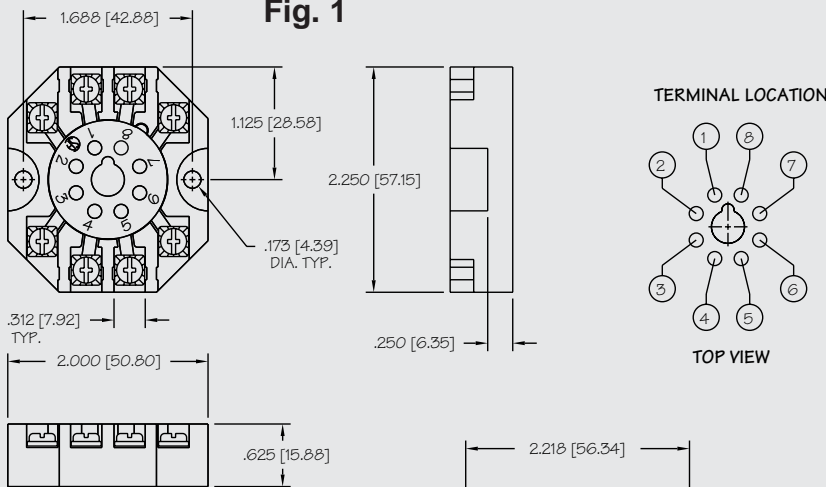

**Fig. 2**

