





 Cross Reference Ra Part Number PP3636

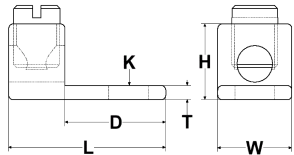

BURNDY Catalog Number
UPC Number
Description
Status

KA40U2N 
781810370452
300-800 NEMA
Active

Web Use
BURNDY Product Line

Dimensional

Width (in) 1.75
Length (in) 4.75
Bolt Hole Size (in) 0.5
Thickness 0.5
D - in 3.03
Pad Width (in) 1.77
E - in 1.75
N (in) 0.63

General

Number of Conductors 1
Number of Holes 2
Product Description Aluminum Universal Terminal, 2 Hole, 300-800 kcmil, 1/2" Stud, 1.75" Stud Hole Spacing, 1 Screw, Al/Cu Rated, Tin Plated

Conductor(s)

Aluminum Size (Range) 300 kcmil-800 kcmil
Copper Solid Size (Range) N/A
Copper Stranded (Range) 300 kcmil-800 kcmil

Physical

Installation Torque 500
Type of Plating Tin
Connector Type Terminal
Bolt Hole Size 1/2
Plated (Yes or No) Y
Product Material Aluminum

Approvals / Certifications

Rated for Direct Burial N
UL Listed Y
CSA Certified Y
ROHS Compatible Exempt
UL Recognized N
CULUS N
Industry Standards UL468A-468B
Documentation

For further technical assistance, please contact us