



CONNECTING YOUR TOMORROW.™

HOME : SALES LOCATIONS : PRODUCTS : CUSTOMER SERVICE : COMPANY : CONTACT US



PRODUCT QUICK SEARCH:

Penn Union Search:

Competitor Search:

Now In: [Penn-Union Products](#) → [Mechanical Lugs & Splices](#) → [Bronze Penn-Lugs](#) → [PNL - 1 Conductor](#) → [PNL-4 - Bronze Penn-Lug](#)



PNL-4 - Bronze Penn-Lug
1-Hole Tongue

For copper wire

The Economy Lug with Quality Improvements

Screw tightens directly on the conductor forcing the conductor into intimate contact with the body for maximum conductivity


Flat bottom allows mounting either on tongue only or with full contact surface

Inspection hole for proper cable insertion

Lug can be furnished electro-tinned or silver plated.

For tin plating add "-TN" to catalog number. For silver plating add "-SV" to catalog number

Product Drawing:

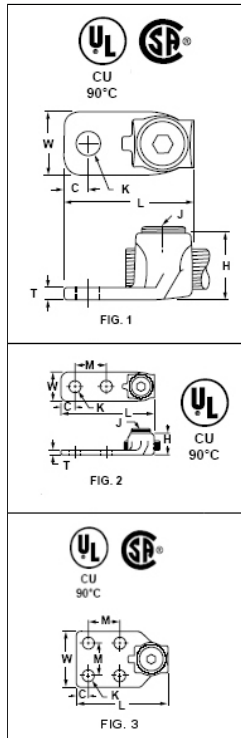

[Click to expand.](#)

Conductor Type	Conductor Range	Wire Diameter (in.)
Copper	14 Sol. - 4 Str.	.064 - .232

No. of Holes in Pad:	1
No. of Conductors:	1

Additional Details	
UL Listing:	CU 90°C
CSA Listing:	Yes

Approximate Dimensions	
Fig. No.:	1
C (in.):	17/64
H (in.):	9/16
J (in.):	5/16-24
K (in.):	17/64
L (in.):	1 1/4
T (in.):	9/64
W (in.):	17/32