
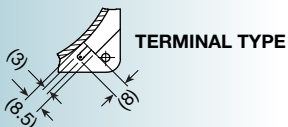


### Cross Reference to Rockwell Part Number 22610-102-02

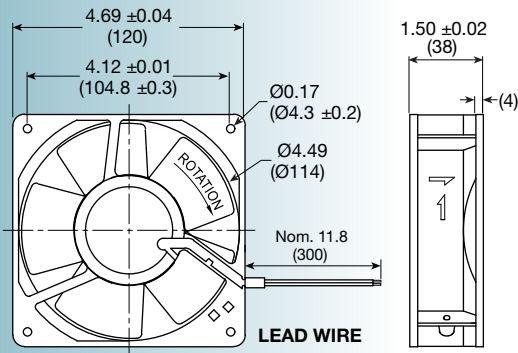

**Size:** (120 x 120 x 38 mm)  
4.69 x 4.69 x 1.5 inches

**Features:** *reverse air flow*  
*(air intake over struts)*

**Operating voltage (VAC):** 115 or 230

**Construction:** aluminum die cast frame;  
UL94V-0 PBT impeller


**Bearing option:** motor quality ball bearings

**Motor:** shaded pole

**Air flow:** intake over struts

**Connection:** terminal or 22 AWG lead wire

**Protection:** impedance

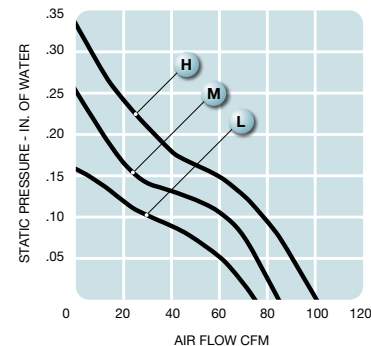

Model No.	Rated Voltage V	Freq. HZ	Input Power W	Rated Cur. A	Locked Cur. A	Speed RPM	Air Volume		Max. Static Pressure (H <sub>2</sub> O)		Sound Noise db	Weight oz
							M <sup>3</sup> /Min.	CFM	MM	INCH		
UF12AR12-__H	115	60	11	0.19	0.20	3,100	2.8	99	8.5	0.33	47	18.7
UF12AR23-__H	230	60	15	0.09	0.10	3,100	2.8	99	8.5	0.33	47	18.7
UF12AR12-__M	115	60	11	0.17	0.19	2,750	2.4	85	6.5	0.26	45	18.7
UF12AR23-__M	230	60	15	0.08	0.09	2,750	2.4	85	6.5	0.26	45	18.7
UF12AR12-__L	115	60	11	0.15	0.16	2,300	2.1	75	4.0	0.16	38	18.7
UF12AR23-__L	230	60	15	0.07	0.08	2,300	2.1	75	4.0	0.16	38	18.7