

# BOTTOM FEED SWITCHES RATED 480 VOLT AC

CROSS REF  
FOR  
25184-257-28


## SERIES VLB (Dwg. 0-1103)

### CATALOG NUMBERS

Amp.	2-P 2-W	2-P 3-W	3-P 3-W	3-P 4-W
800	VLB247	VLB347N	<b>VLB347</b>	VLB447N
1200	VLB248	VLB348N	<b>VLB348</b>	VLB448N
1600	VLB249	VLB349N	<b>VLB349</b>	VLB449N
2000	VLB2410	VLB3410N	<b>VLB3410</b>	VLB4410N
2500	VLB2411	VLB3411N	<b>VLB3411</b>	VLB4411N
3000	VLB2412	VLB3412N	<b>VLB3412</b>	VLB4412N

Shunt Trip Operator, add suffix -ST  
 Motorized Shunt Trip Operator, add suffix -MST

Alternate 600 Volt AC rating on 800-2000 Amp:  
 Replace second number "4" with "6" (i.e. VLB367)

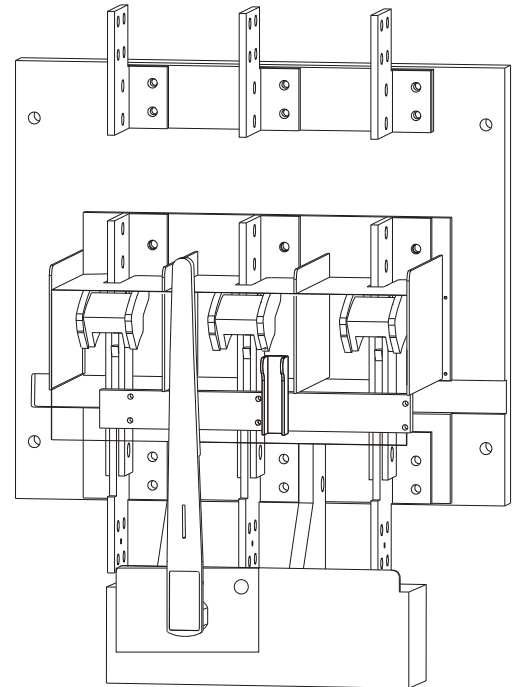


## SERIES SLB (Dwg. 0-1116)

### CATALOG NUMBERS

Amp.	2-P 2-W	2-P 3-W	3-P 3-W	3-P 4-W
4000	SLB2413	SLB3413N	<b>SLB3413</b>	SLB4413N
5000*	SLB2414		<b>SLB3414</b>	
6000*	SLB2415		<b>SLB3415</b>	

Shunt Trip Operator, add suffix -ST  
 Motorized Shunt Trip Operator, add suffix -MST  
 \* Not U.L. Listed

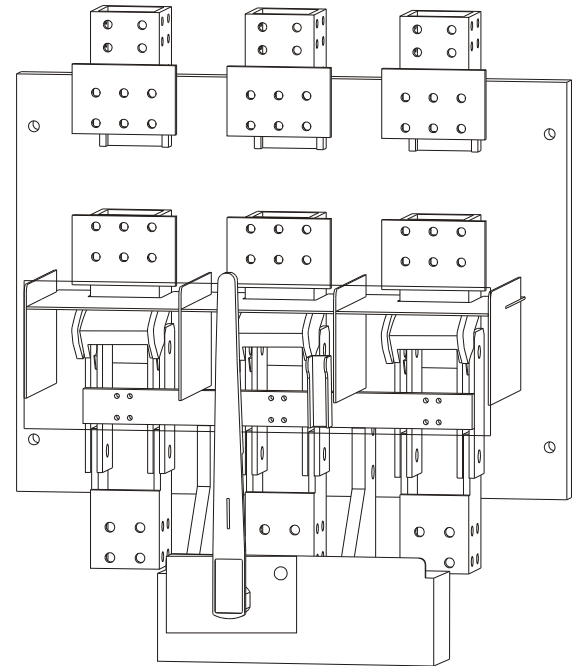

## SERIES VLB & SLB WITH INTEGRAL GROUND FAULT PROTECTION

Switches have integrally mounted ground fault relay and sensor, control transformer, shunt trip operator, and neutral (when applicable). Units are factory wired and tested.

**800-3000 Amp. Dwg. O-1291**

**4000 Amp. Dwg. O-1330**

### CATALOG NUMBERS

Amp.	2-P 3-W 120/240V	3-P 3-W 240V	3-P 4-W 208Y/120V	3-P 4-W 240/120V	3-P 3-W 480V	3-P 4-W 480Y/277V	3-P 4-W 380Y/220V
800	VLB347G1	VLB347G2	VLB347G3	VLB347G4	VLB347G5	<b>VLB347G6</b>	VLB347G9
1200	VLB348G1	VLB348G2	VLB348G3	VLB348G4	VLB348G5	<b>VLB348G6</b>	VLB348G9
1600	VLB349G1	VLB349G2	VLB349G3	VLB349G4	VLB349G5	<b>VLB349G6</b>	VLB349G9
2000	VLB3410G1	VLB3410G2	VLB3410G3	VLB3410G4	VLB3410G5	<b>VLB3410G6</b>	VLB3410G9
2500	VLB3411G1	VLB3411G2	VLB3411G3	VLB3411G4	VLB3411G5	<b>VLB3411G6</b>	VLB3411G9
3000	VLB3412G1	VLB3412G2	VLB3412G3	VLB3412G4	VLB3412G5	<b>VLB3412G6</b>	VLB3412G9
4000	SLB3413G1	SLB3413G2	SLB3413G3	SLB3413G4	SLB3413G5	<b>SLB3413G6</b>	SLB3413G9

Motorized Shunt Trip Operator, add suffix -MST