

Color-Keyed®

**T&B Catalog Number:****5412006****UPC Number:**

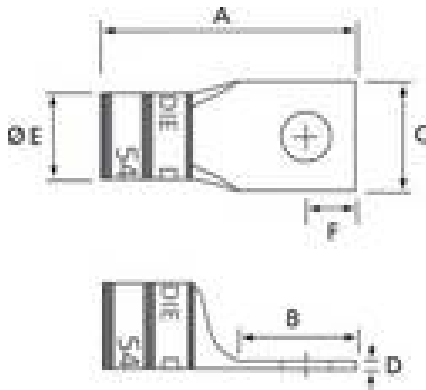
78621087974

Description:

Copper One-Hole Lug - Straight Standard Barrel - max 35KV, 600 kcmil Wire, 3/8" Bolt Size, Tin Plated with Inspection Hole, Green 94

Status:

Active

**General**

Material	Copper
Finish	Tin Plated
Wire Size	600 kcmil
Number of Studs	1
Stud Size	3/8
Tongue Angle	Straight
Barrel Length	Standard
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	Green
Die Code	94

Packaging

T&B Order Multiple	6
T&B Inner Pack	6
Package in Units	60
T&B Sold in UOM	Each
T&B Weight Per UOM	37.3 lbs. per 100

Application Support

T&B Instruction Sheets	ta00884-tb2
Overview	Available on Website
Connector & Tooling Chart	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to +/- .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications

File Nbr:

E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com