

## Rail & Base Mount Terminal Blocks

**CROSS REFERENCE TO ROCKWELL Part No. 40120-818-14**

**MAGNUM**<sup>®</sup>  
GET CONNECTED WITH US

**NC3**

Inches (Millimeters)

### SPECIFICATIONS

**Rating:** 175A, 600V; UL/CSA

**Center spacing:** 1.06" (26.92)

**Number of poles:** 3

**Circuits per foot:** 11

**Wire size:** 2/0-#14 CU/AL

 


**Screw size:** 5/16-24

**Mounting options:** C-rail,  
Base Mount

**Marking tape:** MT12-1/2

**Torque rating:** 45 in/lb max.

**Operating temperature:** 105°C

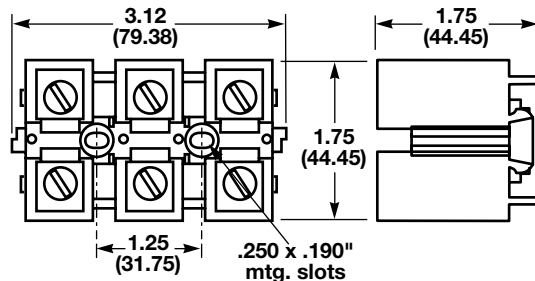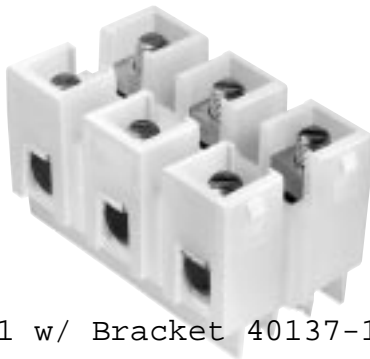

Optional LS3 Terminal Cover

Term Block 22112-316-01 w/ Bracket 40137-187-02