


Cross Reference with 40120-845-07

Product Details and Certifications

Product: 1492-ED103

Description: Panel Mount Block, Pull apart, 3-Pole, Green, Pkg. Qty. of 1

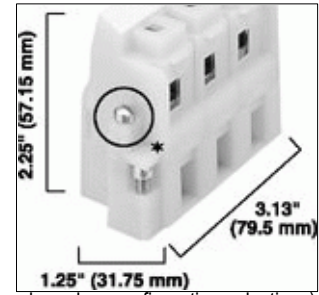

Representative Photo Only (actual product may vary based on configuration selections)

PANEL MOUNT BLOCK DATA

Base Block Type	Pull-Apart Blocks
Number of Poles	3 Pole
Terminal Type	Standard

Certifications and Approvals

UR

CSA

For UL Certifications Directory:

<http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm>

SPECIFICATION SHEET FOR 1492-ED103

Specifications	3-pole terminal block. Pulls apart to disconnect all poles from the circuit.	
Approvals (See Page 12-7)	UL/CSA	
Voltage Rating	600V AC/DC	
Maximum Current (per pole)	60 A	
Wire Range (Rated Cross Section)	#14...#4 AWG (2.5...25 mm ²)	
Wire Strip Length	0.38" (9.7 mm)	
Recommended Tightening Torque	10...30 lb-in. (1.1...3.4 Nm)	
Insulation Temperature Range	-40...+221°F (-40...+105°C)	
Terminal Blocks	Cat. No.	Pcs./Pkg.
Terminal Block:	1492-ED103	1
Accessories (page 12-172)	Cat. No.	Pcs./Pkg.
Anchor Unit: (required every 12th block)	Not Required	—
End Piece	Not Required	—