

➔ Cross Reference RA Part PN-70374

➔ Item # **710-0002** Model 710 Electromechanical Hour Meter



Model 710 Electromechanical Hour Meter

The Model 710 AC hour meters and minute meters are widely used in panel applications where number size and visibility are critical. Its tough, Lexan bezel and distinctive styling enhance appearance and durability. Available in 5 figures reset or 6 figures non-reset versions.

Specifications

| | |
|------------------------------|---|
| Model No. | 710 |
| Mounting | Panel (3-Hole) |
| Reset | Non-reset |
| Termination | Terminal block |
| Display | 6 figures, 99999.9 (non-reset), 0.19 inch (5mm) high |
| Display Height | 0.19 Inch |
| Display Height | 5 mm |
| No. of Digits | 6 |
| Records | 99999.9 hours |
| Input Voltage | 115 VAC 60 Hz \pm 10% |
| Power | 3 watts (nominal) |
| Operating Temperature | -20 to +160 °F |
| Operating Temperature | -29 to +71 °C |
| Weight | 6 oz |
| Weight | 170 gm |
| Mounting Holes | For No. 4 screws on 2.44 inch (62.0mm) B.C. and No. 6 screws on 2.53 inch (64.3mm) B.C. |
| Approvals | UL Recognized, CSA Certified, CE Compliant |
| Stock Availability | Yes |



Description

The model 710 AC hour meters and minute meters are widely used in panel applications where number size and visibility are critical. Its tough, Lexan bezel and distinctive styling enhance appearance and durability. Available in 5 figure reset or 6 figure non-reset versions.

Features

- Large figures
- Tough, Lexan case
- Reset or non-reset

Options

- Private label faceplates
- Bracket mount
- Mounting bracket (721-0003)
- Splash proof kit (721-0017)
- Heavy duty splash proof kit (721-0018)
- Gasket (721-0004)

Specifications

Figures: 5 figures, 9999.9 (reset) or 6 figure, 99999.9 (non-reset), 0.19" [5mm] high
Reset: Reset (on front or side) or non-reset
Voltages: 24, 115 or 230VAC, (+/-10%), 50 or 60 Hz.
Power: 3 watts (nominal)
Mounting: Panel (3-hole)

Terminations: 8" [203.2mm] wire leads or terminal block
Temp. Range: -20°F to +160°F [-29°C to +71°C]
Approvals: UL Recognized, CSA Certified, CE Compliant
Weight: 6 oz. [170g]

Models

Description

Models

Description


710-0001 115VAC/60Hz, non-reset, 99,999.9 hrs, 8" [203mm] wire leads
710-0002 115VAC/60Hz, non-reset, 99,999.9 hrs, terminal block
710-0003 230VAC/60Hz, non-reset, 99,999.9 hrs, 8" [203mm] wire leads
710-0006 24VAC/60Hz, non-reset, 99,999.9 hrs, 8" [203mm] wire leads
710-0008 115VAC/60Hz, non-reset, 99,999 hrs, 8" [203mm] wire leads
710-0009 115VAC/50Hz, non-reset, 99,999.9 hrs, 8" [203mm] wire leads
710-0013 115VAC/60Hz, front reset, 9,999.9 hrs, 8" [203mm] wire leads

710-0014 230VAC/60Hz, non-reset, 99,999.9 hrs, terminal block
710-0018 115VAC/60Hz, non-reset, 99,999.9 min, 8" [203mm] wire leads
710-0024 24VAC/60Hz, non-reset, 99,999.9 hrs, terminal block
710-0026 115VAC/50Hz, non-reset, 99,999.9 hrs, terminal block
710-0032 115VAC/60Hz, front reset, 9,999.9 hrs, terminal block
710-0051 115VAC/60Hz, non-reset, 99,999 hrs, terminal block

* Items in bold are normally in factory stock.

Dimensions

8" [203mm] Wire Leads

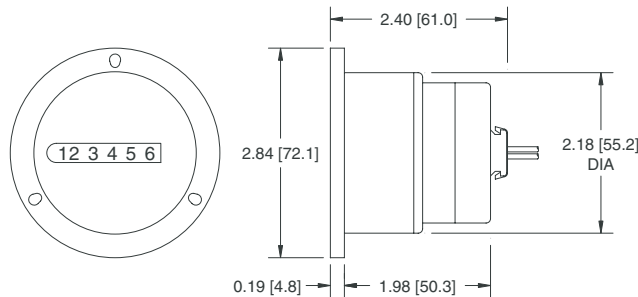

Mounting holes: For #4 screws on 2.44" [62.0] B.C.
 and #6 screws on 2.53" [64.3] B.C.
 Panel cutout: 2.21" [56.1] Dia.

Applications


Office equipment



Control panels



Industrial equipment

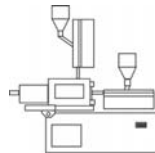

Test equipment



Compressors

