

Color-Keyed®

**T&B Catalog Number:****54874BE****UPC Number:**

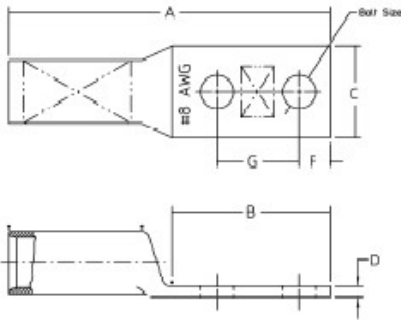
78621089808

Description:

Copper Two-Hole Lug - Straight Long Barrel - max 35KV, 400 kcmil Wire, 1/2" Bolt Size, 1 3/4" Hole Spacing, Tin Plated Blind End, Blue 76

Status:

Active

**General**

Material	Copper
Finish	Tin Plated
Wire Size	400 kcmil
Number of Studs	2
Stud Size	1/2
Bolt Hole Spacing	1 3/4
Tongue Angle	Straight
Barrel Length	Long
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	N
Marking	Standard
Hole Shape	Round
Die Color	Blue
Die Code	76

Dimension Information

A (inches)	5.453
B (inches)	2.984
C (inches)	1.406
D (inches)	0.172
E (inches)	0.953
F (inches)	0.5
G (inches)	1.75

Packaging

T&B Order Multiple	6
T&B Inner Pack	6
Package in Units	60
T&B Sold in UOM	Each
T&B Weight Per UOM	45.33 lbs. per 100

Application Support

T&B Instruction Sheets	ta01025-tb2
Overview	Available on Website
Connector & Tooling Chart	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to +/- .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com