



## MIDGET STRIP SERIES

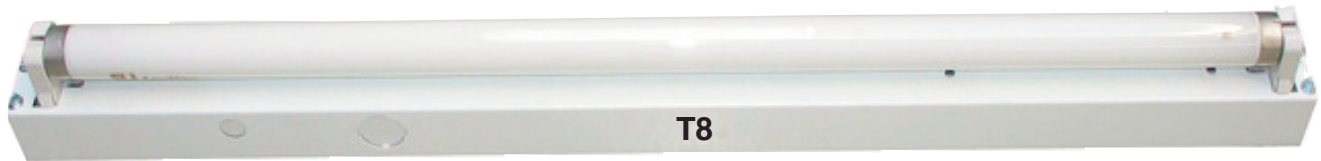

### DESCRIPTION

A small and simple fluorescent strip fixture configured with one lamp on top. Just right for commercial and industrial installations where concealed light is needed with a small footprint. Uses T5, T8, or compact biax lamps.

Mounting: Fixtures designed for direct surface mount. Can be installed as individual units, in continuous rows or in conjunction with other fixtures.

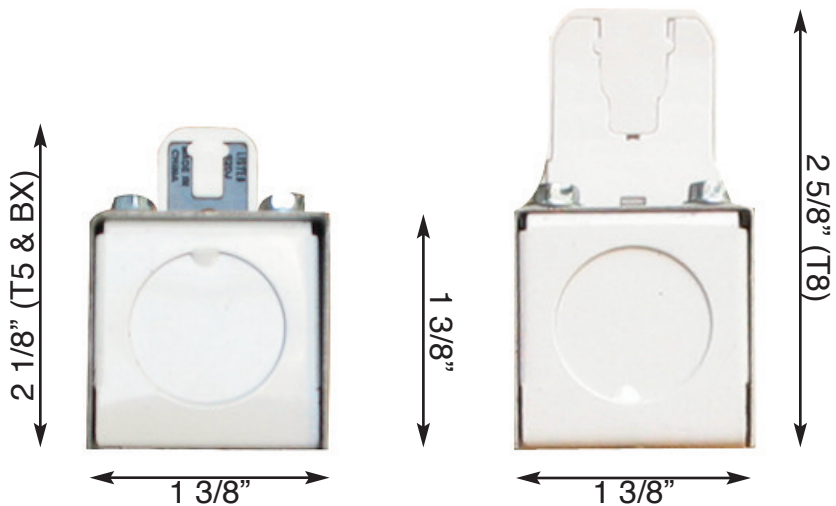

### CONSTRUCTION

Housing: Die-formed 21-gauge cold rolled steel.

Cover: Screw-on die-formed white steel.

Finish: Phosphate coated, baked white enamel with 85% reflectivity.

### ELECTRICAL

120v, 60Hz, solid state electronic high power factor ballast, direct wire, UL/CUL listed for dry or damp locations.

### OPTIONS

Add "SJT" for grounded cord & plug, specify length.

Add "277" for 277 volt ballast.

### ORDERING INFORMATION

<u>Model Number</u>	<u>Lamps</u>	<u>Length (L)</u>
<b>T5</b>		
MS104E	(1) F4T5	9"
MS106E	(1) F6T5	12"
MS108E	(1) F8T5	15"
<b>Biax CFL</b>		
MS107M/BX	(1) F7BX	9"
MS109M/BX	(1) F9BX	9"
MS113M/BX	(1) F13BX	9"
<b>T8</b>		
MS115E	(1) F15T8	21"
MS215T/E	(2) F15T8	41"