





CONNECTING YOUR TOMORROW.™

HOME : SALES LOCATIONS : PRODUCTS : CUSTOMER SERVICE : COMPANY : CONTACT US

➔ Cross Reference RA Part X-314129

Now In: [Penn-Union Products](#) → [Mechanical Lugs & Splices](#) → [Bronze Penn-Lugs](#) → [PNL - 1 Conductor](#) → PNL-500 - Bronze Penn-Lug

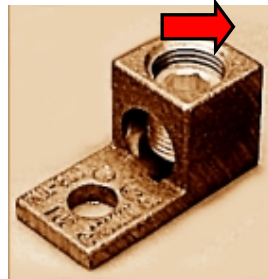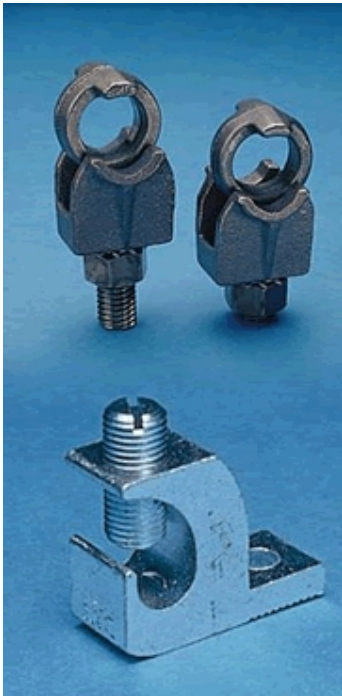

PNL-500 - Bronze Penn-Lug

1-Hole Tongue

For copper wire

The Economy Lug with Quality Improvements

Screw tightens directly on the conductor forcing the conductor into intimate contact with the body for maximum conductivity


Flat bottom allows mounting either on tongue only or with full contact surface

Inspection hole for proper cable insertion

Lug can be furnished electro-tinned or silver plated.

For tin plating add "-TN" to catalog number. For silver plating add "-SV" to catalog number

Product Drawing:

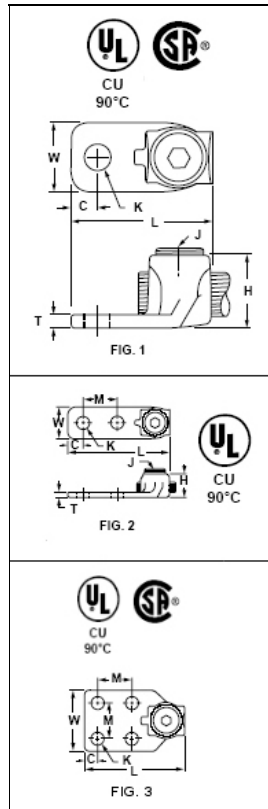

Conductor Type	Conductor Range	Wire Diameter (in.)
Copper	4 Sol. - 500 MCM	.204 - .815

No. of Holes in Pad:	1
No. of Conductors:	1

Additional Details

Wrench Size:	3/8
UL Listing:	CU 90°C
CSA Listing:	Yes

Approximate Dimensions

Fig. No.:	1
C (in.):	3/4
H (in.):	1 15/32
J (in.):	15/16-16
K (in.):	17/32
L (in.):	3
T (in.):	1/4
W (in.):	1 3/8

[Click to expand.](#)

PRODUCT QUICK SEARCH:

Penn Union Search:

Search

Competitor Search:

Search