

Now In: [Penn-Union Products](#) → [Mechanical Lugs & Splices](#) → [Bronze Penn-Lugs](#) → [PNL - 1 Conductor](#) → PNL-1/0 - Bronze Penn-Lug


## PNL-1/0 - Bronze Penn-Lug

1-Hole Tongue

For copper wire

The Economy Lug with Quality Improvements

Screw tightens directly on the conductor forcing the conductor into intimate contact with the body for maximum conductivity

Flat bottom allows mounting either on tongue only or with full contact surface

Inspection hole for proper cable insertion

### Product Drawing:

Locking boss available at an additional cost, contact factory

Lug can be furnished electro-tinned or silver plated.

For tin plating add "-TN" to catalog number. For silver plating add "-SV" to catalog number


Conductor Type	Conductor Range	Wire Diameter (in.)
Copper	8 Sol. - 1/0 Str.	.128 - .375

<b>No. of Holes in Pad:</b>	1
<b>No. of Conductors:</b>	1

Additional Details	
<b>Wrench Size:</b>	1/4
<b>UL Listing:</b>	CU 90°C
<b>CSA Listing:</b>	Yes

Approximate Dimensions	
<b>Fig. No.:</b>	1
<b>C (in.):</b>	3/8
<b>H (in.):</b>	25/32
<b>J (in.):</b>	1/2-20

### PRODUCT QUICK SEARCH:

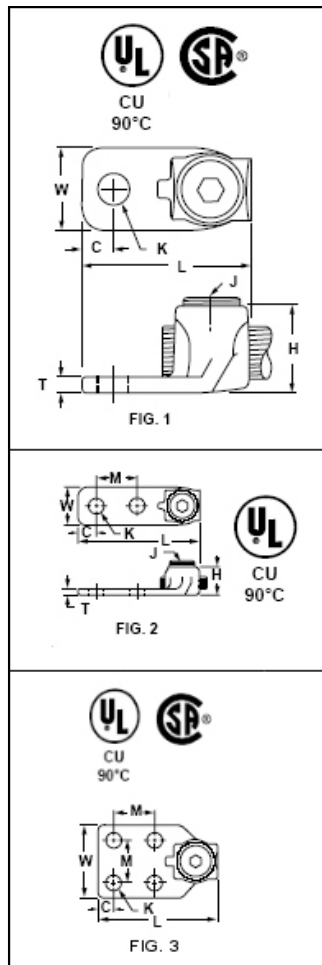

[Click to expand.](#)

<b>K (in.):</b>	21/64
<b>L (in.):</b>	1 19/32
<b>T (in.):</b>	9/64
<b>W (in.):</b>	47/64



© 2008 Penn-Union Corp. · 229 Waterford Street · Edinboro, PA 16412  
 Phone: 814-734-1631 · Fax: 814-734-4946 · [info@penn-union.com](mailto:info@penn-union.com)

Designed & Developed by O-Web Technologies, Ltd.